


Flexible Shafts

GTC-701/GTC-702/GTC-703/GTC-704/GTC-720


PATENTED

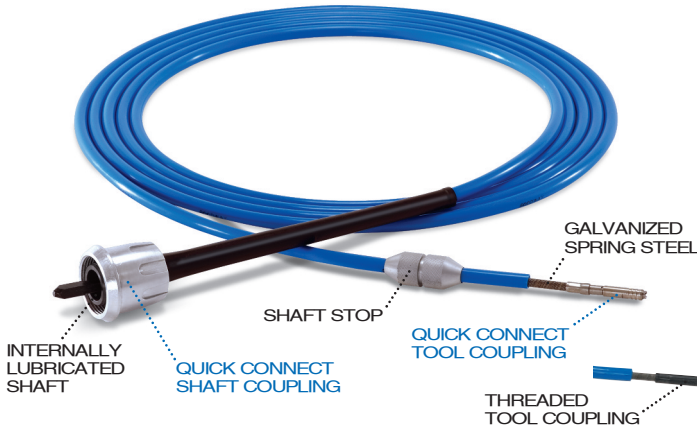

FEATURES

- > Abrasion Resistant Blue Nylon Casing provides high visibility for safety and a toughest exterior to withstand harsh industrial environments
- > Internally Lubricated Shaft Insert molded out of a self lubricating material reduces friction and increases shaft life
- > Metal Nut provides a secure connection to the drive unit without any concern for breakage
- > Strain Relief System custom molded with a variable thickness allows for a gradual radial bend that is far superior to a spring or coiled wire
- > Shaft Stop which can be positioned anywhere along the shaft lets you know when the end of the tube has been reached
- > Quick Connect Couplings allow you to change shafts, brushes and cleaning tools up to 30 times faster than on shafts with threaded connections
- > Galvanized Spring Steel comprised of multiple counter rotated windings provides unmatched performance and long durability

Flexible Shaft Dimensions					
Shaft No.	Casing O.D.	Tool End Thread	Shaft No.	Casing O.D.	Tool End Thread
701	6,4 mm	8-32 female	720	19,1 mm	1/2-12 female
702	9,5 mm	1/4-28 female	721	22,2 mm	1/2-12 female
703	12,7 mm	1/4-28 female	721G	22,2 mm	1/2-12 female
704	14,3 mm	1/4-28 female	821	22,2 mm	1/2-12 female

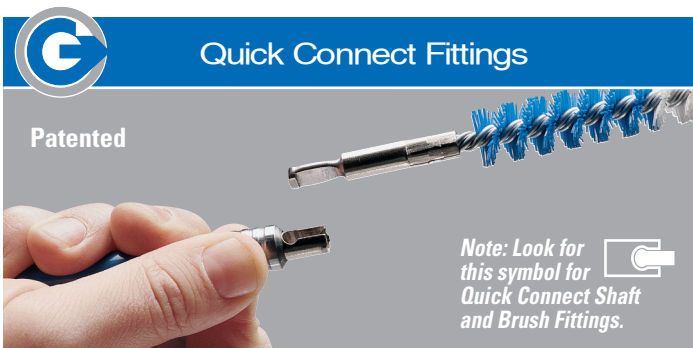

WET / DRY APPLICATIONS

Flexible Shafts (Nylon Casing) for Tubes 6,4 to 9,5 mm I.D.

GTC-701-12 Flexible Shaft, 3,7 m

GTC-701-25 Flexible Shaft, 7,6 m

Flexible Shafts (Nylon Casing) for Tubes 11,1 to 12,7 mm I.D.

GTC-702Q-12 Flexible Shaft, 3,7 m

GTC-702Q-17 Flexible Shaft, 5,2 m

GTC-702Q-25 Flexible Shaft, 7,6 m

GTC-702Q-35 Flexible Shaft, 10,7 m

GTC-702Q-45 Flexible Shaft, 13,7 m



Flexible Shafts (Nylon Casing) for Tubes 14.3 to 25.4 mm I.D.

GTC-703Q-12 Flexible Shaft, 3,7 m

GTC-703Q-17 Flexible Shaft, 5,2 m

GTC-703Q-25 Flexible Shaft, 7,6 m

GTC-703Q-35 Flexible Shaft, 10,7 m

GTC-703Q-45 Flexible Shaft, 13,7 m

GTC-703Q-60 Flexible Shaft, 18,3 m

GTC-703Q-75 Flexible Shaft, 22,9 m



Flexible Shafts (Nylon Casing) for Tubes 17,5 to 25,4 mm I.D.

GTC-704Q-12 Flexible Shaft, 3,7 m

GTC-704Q-17 Flexible Shaft, 5,2 m

GTC-704Q-25 Flexible Shaft, 7,6 m

GTC-704Q-35 Flexible Shaft, 10,7 m

GTC-704Q-45 Flexible Shaft, 13,7 m

GTC-704Q-60 Flexible Shaft, 18,3 m

GTC-704Q-75 Flexible Shaft, 22,9 m



Note: GTC-702Q, GTC-703Q and GTC-704Q Flexible Shafts are available with standard threaded tool couplings. To order leave off the "Q" in the part number.

Note: GTC-703, GTC-703Q, GTC-704 and GTC-704Q Flexible Shafts for use with a RAM-5SF Speed-Feed Tube Cleaner require a special shaft stop. To order, add the suffix R5 to the part number.

Flexible Shafts (Nylon Casing) for Tubes 25,4 mm I.D. and Up

GTC-720-15 Flexible Shaft, 4,6 m

GTC-720-25 Flexible Shaft, 7,6 m

GTC-720-35 Flexible Shaft, 10,7 m

GTC-720-50 Flexible Shaft, 15,2 m



DRY APPLICATIONS

Flexible Shafts (Covered Steel Casing) for Tubes 25,4 mm I.D. and Up

GTC-721-15 Flexible Shaft, 4,6 m

GTC-721-25 Flexible Shaft, 7,6 m

GTC-721-35 Flexible Shaft, 10,7 m

GTC-721-50 Flexible Shaft, 15,2 m



Flexible Shafts (Heat Resistant 149°C Rigid Covered Steel Casing) for Tubes 25,4 mm I.D. and Up

GTC-721G-15 Flexible Shaft, 4,6 m

GTC-721G-25 Flexible Shaft, 7,6 m

GTC-721G-35 Flexible Shaft, 10,7 m

GTC-721G-50 Flexible Shaft, 15,2 m



Flexible Shafts (High Temperature Tolerant 232°C Stainless Steel Casing) for Tubes 25,4 mm I.D. and Up

GTC-821-15 Flexible Shaft, 4,6 m

GTC-821-25 Flexible Shaft, 7,6 m

GTC-821-35 Flexible Shaft, 10,7 m

GTC-821-50 Flexible Shaft, 15,2 m

