


## ロングニップル

単位 mm

金型冷却用延長継手

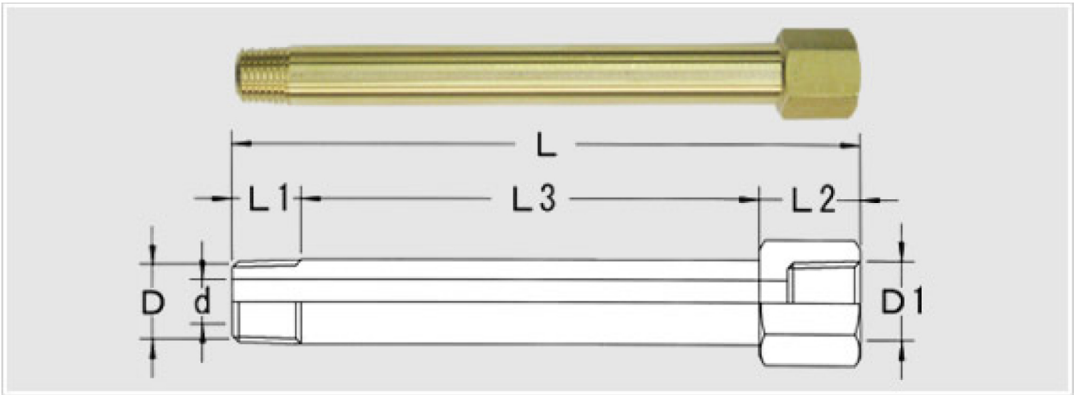

規格	オネジD	メネジD1	L	L1	L2	L3	d	六角対辺
LN1/8 × 50 EA141AK-50	R1/8	Rc1/8	50	9	13	28	6	14
LN1/8 × 70 EA141AK-70	R1/8	Rc1/8	70	9	13	48	6	14
LN1/8 × 80 EA141AK-80	R1/8	Rc1/8	80	9	13	58	6	14
LN1/8 × 100 EA141AK-100	R1/8	Rc1/8	100	9	13	78	6	14
LN1/8 × 130 EA141AK-130	R1/8	Rc1/8	130	9	13	108	6	14
LN1/8 × 150 EA141AK-150	R1/8	Rc1/8	150	9	13	128	6	14
LN1/8 × 200 EA141AK-200	R1/8	Rc1/8	200	9	13	178	6	14
LN1/4 × 50 EA141AL-50	R1/4	Rc1/4	50	11	16	23	7	17
LN1/4 × 70 EA141AL-70	R1/4	Rc1/4	70	11	16	43	7	17
LN1/4 × 80 EA141AL-80	R1/4	Rc1/4	80	11	16	53	7	17
LN1/4 × 100 EA141AL-100	R1/4	Rc1/4	100	11	16	73	7	17
LN1/4 × 130 EA141AL-130	R1/4	Rc1/4	130	11	16	103	7	17
LN1/4 × 150 EA141AL-150	R1/4	Rc1/4	150	11	16	123	7	17
<b>LN1/4 × 180</b> EA141AL-180	R1/4	Rc1/4	180	11	16	153	7	17
LN1/4 × 200 EA141AL-200	R1/4	Rc1/4	200	11	16	173	7	17