

単位 mm


ロング水口M

金型冷却用ホース継手

ホース口 二段溝



規格	EA品番	ホース口 d	ネジ D	六角 対辺	L	L1	L2	L3	d1
LM1/8 × 50	EA141AN-80	12.5	R1/8	14	80	50	21	9	6
LM1/8 × 70	EA141AN-100				100	70			
LM1/8 × 100	EA141AN-130				130	100			
LM1/4 × 70	EA141AP-100	12.5	R1/4	17	100	70	21	11	7
LM1/4 × 100	EA141AP-130				130	100			
LM1/4 × 130	EA141AP-160				160	130			
LM1/4 × 150	EA141AP-180				180	150			

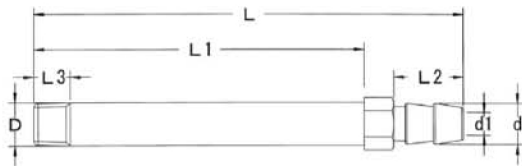

ロング水口M使用材料
■黄銅棒