
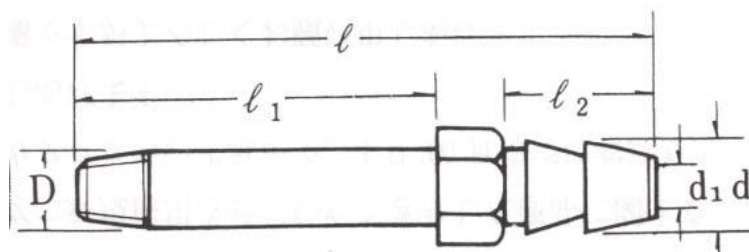


EA141AN-80~AP-180 ロング水口(ホース口 二段溝)

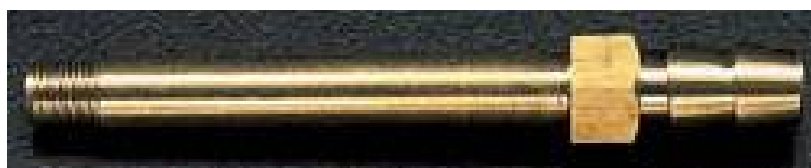

材質:真鍮	ホース口 d	ネジ D	l	l_1	l_2	d_1	六角対辺
EA141AN-80	12.5	PT1/8	80	50	21	6	14
廃番 EA141AN-100	12.5	PT1/8	100	70	21	6	14
EA141AN-130	12.5	PT1/8	130	100	21	6	14
廃番 EA141AN-160	12.5	PT1/8	160	130	21	6	14
廃番 EA141AN-180	12.5	PT1/8	180	150	21	6	14

廃番 EA141AP-100	12.5	PT1/4	100	70	21	7	14
EA141AP-130	12.5	PT1/4	130	100	21	7	14
廃番 EA141AP-160	12.5	PT1/4	160	130	21	7	14
廃番 EA141AP-180	12.5	PT1/4	180	150	21	7	14