


# ロング水口M (在庫僅少品)

金型冷却用ホース継手

ホース口 二段溝

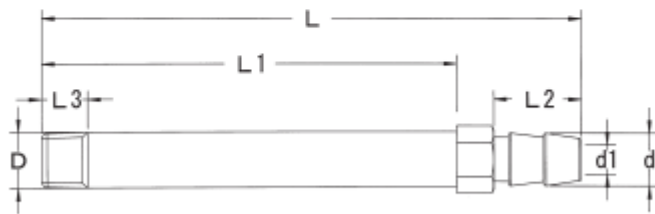

| 規 格        | ホース口<br>d | ネジ<br>D | 六角<br>対辺 | L   | L1  | L2 | L3 | d1 |
|------------|-----------|---------|----------|-----|-----|----|----|----|
| LM1/8× 50  | 12.5      | R1/8    | 14       | 80  | 50  | 21 | 9  | 6  |
| LM1/8× 70  |           |         |          | 100 | 70  |    |    |    |
| LM1/8× 100 |           |         |          | 130 | 100 |    |    |    |
| LM1/8× 130 |           |         |          | 160 | 130 |    |    |    |
| LM1/8× 150 |           |         |          | 180 | 150 |    |    |    |
| LM1/8× 170 |           |         |          | 200 | 170 |    |    |    |
| LM1/8× 200 |           |         |          | 230 | 200 |    |    |    |
| LM1/4× 50  | 12.5      | R1/4    | 14       | 80  | 50  | 21 | 11 | 7  |
| LM1/4× 70  |           |         |          | 100 | 70  |    |    |    |
| LM1/4× 100 |           |         |          | 130 | 100 |    |    |    |
| LM1/4× 130 |           |         |          | 160 | 130 |    |    |    |
| LM1/4× 150 |           |         |          | 180 | 150 |    |    |    |
| LM1/4× 170 |           |         |          | 200 | 170 |    |    |    |
| LM1/4× 200 |           |         |          | 230 | 200 |    |    |    |

ロング水口M使用材料

■黄銅棒