


継手部品

メッキ無をご希望の際は、規格にNを付けて下さい。
規格に (N) が無い製品の場合、メッキ付のみとなります。

No.12 ホース継手

(Rネジ)

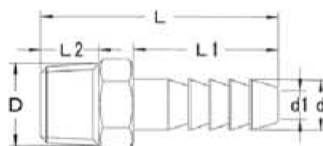

規 格	EA品番	ネジD	d	d1	L	L1	L2	六角 対辺
No.12×1/8	EA141AS-101	R1/8	7	4	33	20	8	10
No.12×1/4	EA141AS-104	R1/4	8.5	5	42	25	11	14
No.12×3/8	EA141AS-109	R3/8	11	6	49	30	12	17
No.12×3/4	EA141AS-119	R3/4	20.5	13	71	45	17	28
No.12×1/8×8.5	EA141AS-102	R1/8	8.5	5	33	20	8	10
No.12×1/4×7	EA141AS-103	R1/4	7	4	37	20	11	14
No.12×1/4×11	EA141AS-105	R1/4	11	6	42	25	11	14
No.12×1/4×12.7	EA141AS-106	R1/4	12.7	7.5	47.5	30	11	14
No.12×3/8×7	EA141AS-107	R3/8	7	4	39	20	12	17
No.12×3/8×8.5	EA141AS-108	R3/8	8.5	5	44	25	12	17
No.12×3/8×12.7	EA141AS-110	R3/8	12.7	7.5	49	30	12	17
No.12×3/8×14.5	EA141AS-111	R3/8	14.5	9	54	35	12	17
No.12×1/2×8.5	EA141AS-112	R1/2	8.5	5	49	25	15	22
No.12×1/2×11	EA141AS-113	R1/2	11	6	54	30	15	22
No.12×1/2×12.7	EA141AS-114	R1/2	12.7	7.5	54	30	15	22
No.12×1/2×17.5	EA141AS-116	R1/2	17.5	11.5	59	35	15	22
No.12×1/2×20.5	EA141AS-117	R1/2	20.5	13	66	42	15	22
No.12×3/4×14.5	EA141AS-118	R3/4	14.5	9.5	61	35	17	28

■材質 黄銅棒C3604 ■表面処理 クロームメッキ