


## 継手部品

規格に (N) が無い製品の場合、メッキ付となります。

## No.06 ニップル

(Rネジ×Rネジ)

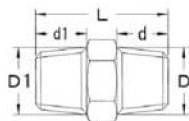

■材質 黄銅棒C3604 ■表面処理 クロームメッキ

規格	ネジ D1	ネジD	L	d1	d	六角 対辺	EA品番	
							メッキ付	メッキ無
No.06 × 1/8 (N)	R1/8	R1/8	21	8		10	EA141AV-301	EA141AV-351
No.06 × 1/4 (N)	R1/4	R1/4	28	11		14	EA141AV-303	EA141AV-353
No.06 × 3/8 (N)	R3/8	R3/8	31	12		17	EA141AV-306	EA141AV-356
No.06 × 1/2 (N)	R1/2	R1/2	38	15		22	EA141AV-308	EA141AV-359
No.06 × 3/4 (N)	R3/4	R3/4	44	17		28	EA141AV-310	EA141AV-361
No.06 × 1/4 × 1/8 (N)	R1/4	R1/8	25	11	8	14	EA141AV-302	EA141AV-352
No.06 × 3/8 × 1/8 (N)	R3/8	R1/8	27	12	8	17		EA141AV-354
No.06 × 3/8 × 1/4 (N)	R3/8	R1/4	30	12	11	17	EA141AV-305	EA141AV-355
No.06 × 1/2 × 1/4 (N)	R1/2	R1/4	34	15	11	22		EA141AV-357
No.06 × 1/2 × 3/8 (N)	R1/2	R3/8	35	15	12	22	EA141AV-307	EA141AV-358
No.06 × 3/4 × 1/2 (N)	R3/4	R1/2	42	17	15	28	EA141AV-309	