


Steam Screwings

Thread Screwings (DIN EN 14 423)

Female thread screwings made of steel (zinc-plated and yellow passivated, free of chrome VI) with safety clamp made of brass

Hose connect.	Thread connect.	L	SW	B	L1	DN	Passage	Weight	Type No.
Hose 13x6	G 1/2 f	88	27	53	11	15	9	480	DIK 12-13 ST EA141BM-4
Hose 19x7	G 3/4 f	92	32	68	15	20	14	680	DIK 34-19 ST EA141BM-6
Hose 25x7.5	G 1 f	93	41	77	16	25	20	1022	DIK 10-25 ST EA141BM-8
Hose 38x8	G 1 1/2 f	120	55	101	18	40	33	1930	DIK 15-38 ST EA141BM-14
Hose 50x9	G 2 f	131	70	111	19	50	44	2613	DIK 20-50 ST EA141BM-20


Attention: Replace female thread sealing ring when screwing is reused!

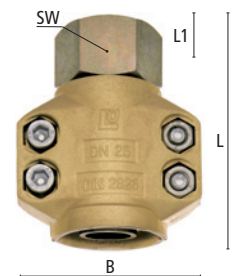

Female thread screwings made of brass MS 58 with safety clamp made of brass

Hose connect.	Thread connect.	L	SW	B	L1	DN	Passage	Weight	Type No.
Hose 13x6	G 1/2 f	88	27	53	11	15	9	480	DIK 12-13 MS
Hose 19x7	G 3/4 f	92	32	68	15	20	14	680	DIK 34-19 MS
Hose 25x7.5	G 1 f	93	41	77	16	25	20	1022	DIK 10-25 MS
Hose 38x8	G 1 1/2 f	120	55	101	18	40	33	1930	DIK 15-38 MS
Hose 50x9	G 2 f	131	70	111	19	50	44	2613	DIK 20-50 MS

Attention: Replace female thread sealing ring when screwing is reused!

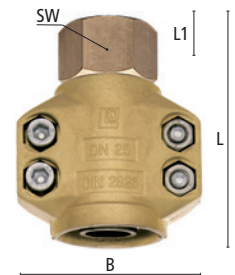

Female thread screwings made of stainless steel 1.4305 with safety clamp made of brass

Hose connect.	Thread connect.	L	SW	B	L1	DN	Passage	Weight	Type No.
Hose 13x6	G 1/2 f	88	27	53	11	15	9	530	DIK 12-13 SS EA141BM-104
Hose 19x7	G 3/4 f	92	32	68	15	20	14	700	DIK 34-19 SS EA141BM-106
Hose 25x7.5	G 1 f	93	41	77	16	25	20	950	DIK 10-25 SS EA141BM-108

