


EA153MC-1~MC-8(サイレンサー)


すべて取扱中止になりました

品番	R	Bφ	C	D	Eφ	SW	重量
	取付ネジ						g
EA153MC-1	M5	6	14	5	-	7	1.7
EA153MC-2	M6	8.2	25	5	-	10	5
EA153MC-3	G1/8"	12.5	25	7	6.5	14	9
EA153MC-4	G1/4"	14	28	8	8	17	13
EA153MC-5	G3/8"	18	30	10	12	20	18
EA153MC-6	G1/2"	22	37	12	16	24	33
EA153MC-7	G3/4"	30	52	14	19	32	75
EA153MC-8	G1"	33	52	16	25	36	95

- 材質…本体:アルミ、網:ステンレス
- 雄ネジ式
- 最大許容圧力…2.5Mpa

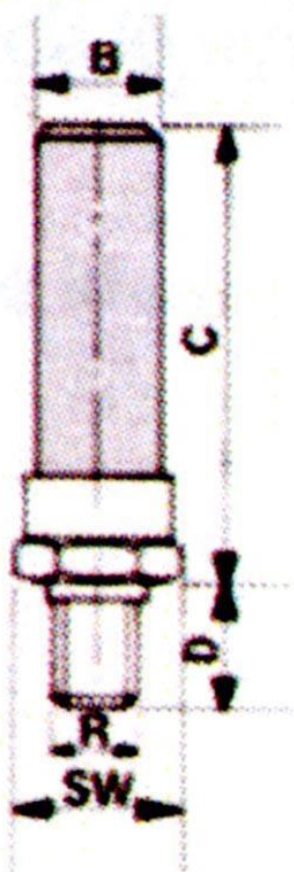

EA153MC-1、-2

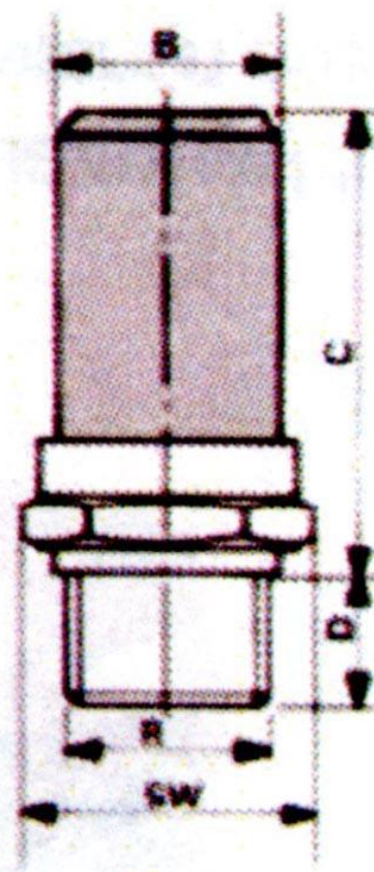

EA153MC-3~-8