


14305M (mm)	D ₁ (mm)	D ₂ (mm)	H ₁ (mm)	H ₂ (mm)	L (mm)	重量 (g)	包装個数 (pcs.)	対応 リング・ピン	
8	14.5	25	8	62	80	137	10	*1	-208
10	17	25	10	62	80	140	10	*1	-210
11	18.2	25	11	62	80	156	10	*1	-211
12	19.5	25	12	62	80	162	10	*1	-212
13	20.7	25	13	62	80	162	10	*1	-213
14	22	25	14	62	80	174	10	*1	-214
15	23.2	30	15	62	80	220	10	*2	-215
16	24.5	30	16	62	80	232	10	*2	-216
17	25.7	30	17	62	80	232	10	*2	-217
18	27	30	18	62	80	232	10	*2	-218
19	28.2	30	19	61	80	259	10	*2	-219
20	29.5	30	20	61	80	265	10	*2	-220
21	30.7	30	21	61	80	265	10	*2	-221
22	32	30	22	65	85	290	10	*2	-222
23	33.2	30	23	65	85	300	10	*2	-223
24	34.5	30	24	65	85	329	10	*2	-224
26	37	30	26	64	85	350	10	*2	-226
27	38.2	30	27	64	85	385	10	*2	-227
28	39.5	30	30	64	85	390	10	*2	-228
29	40.7	30	29	63	85	416	10	*2	-229
30	42	30	30	63	85	457	10	*2	-230
32	44.5	30	32	63	85	542	10	*2	-232
33	45.7	30	33	62	85	562	2	*2	-233
36	49.5	30	36	61	85	635	2	*2	-236

14305M 12角ディープソケット

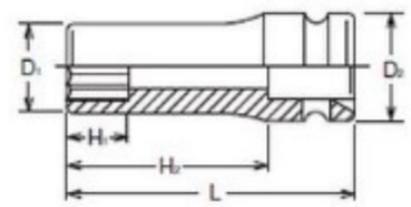

*1 Cリング=1401C/ピン・Oリング=1401A・Bに対応
 *2 Cリング=1402C/ピン・Oリング=1402A・Bに対応