


EA164ED-17-38 (3/4")ホイールナット用薄肉ソケット

6ポイント
差込角 3/4"

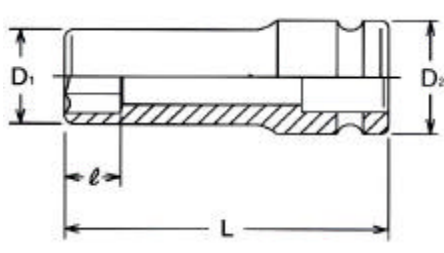

品番	対辺 (mm)	D1(mm)	D2(mm)	l(mm)	L(mm)	適用ピン	適用Oリング	重量(g)
EA164ED-17	17	28	44	17	100	EA164AA -5.5A	EA164A -36	555
EA164ED-19	19	30.5	44	19	100			580
EA164ED-21	21	33	44	21	100			610
EA164ED-22	22	34.3	44	22	100			620
EA164ED-24	24	36.8	44	24	100			640
EA164ED-27	27	40.5	44	27	100			690
EA164ED-29	29	43	44	29	100			685
EA164ED-30	30	44.3	44	30	100			720
EA164ED-32	32	46.8	44	32	100			810
EA164ED-33	33	48	44	33	100			852
EA164ED-34	34	49.3	44	34	100			880
EA164ED-36	36	52.8	44	36	100			889
EA164ED-38	38	54.3	44	38	100			917

(例)

