


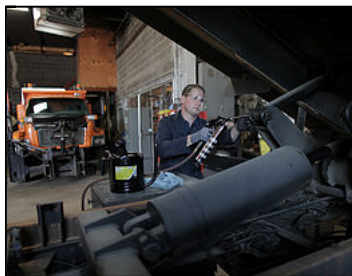

LX-1161 Continuous Cycle, Air Operated Grease Gun

(EA166DN-10A)



Product Details

Part Number: LX-1161


Description:

The Ultimate, Professional Grease Gun. Designed Specifically for Heavyduty, Continuous Cycle use. It is built for the Professionals.

Specifications:

- Ergonomically Designed and Perfectly Balanced for Comfort with Convenience of One-hand Operation for easy greasing
- Patented Air Motor : Enables you to Speed-up lubrication
- Compact Design facilitates work in Tight Spaces
- 1/4" NPT Inlet Outlet: 3/8-32 UNEF
- Working Air Pressure of 40-150 PSI
- Maximum Operating Pressure: 6000 PSI (414 BAR)
- Pump Ratio: 40:1
- Low operational Noise
- Exclusive Valve Design eliminates Trapped Air
- Self-priming
- Versatile 3-way loading: Cartridge, Bulk or with a Pump
- Heavy-duty, Die Cast Head for Durability and Long Life
- Heavy Gauge Steel Barrel With Band, Non-Slip Knurling
- Fully Chrome Plated Finish for Maximum Protection against Corrosion
- Tough and Resilient Follower eliminates grease bypass and allows a Superior Seal for either Cartridge or Bulk Loading applications
- Heavy-duty Follower Spring for Consistent Priming
- Equipped with Air Bleeder and Filler Valves
- Posi-lock Follower Rod with Ergonomically Designed T-handle provides Positive Grip and Easy Filling at any position
- Complete with 30" Hose with 2 Springs (LX-1212) and standard coupler (LX-1400)

Recommended Accessories

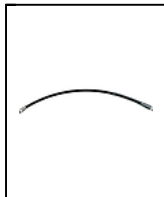


LX-1209

18" Thermoplastic with Spring, 7,500 PSI



LX-1211

18" Thermoplastic with 2 Springs, 7,500 PSI

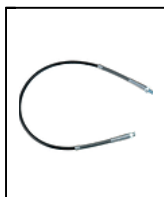

LX-1212

30" Thermoplastic with 2 Springs, 7,500 PSI