

(プロパン・天然ガス用 火口)

	呼び	穴径
EA300BH-3	#100	0.9mm
EA300BH-4	#140	1.0mm
EA300BH-5	#200	1.2mm
EA300BH-6	#225	1.3mm
EA300BH-7	#250	1.4mm
EA300BH-8	#315	1.5mm
EA300BH-9	#400	1.6mm
EA300BH-10	#450	1.7mm
EA300BH-11	#500	1.8mm
EA300BH-12	#630	2.0mm



(先端拡大)

○プロパン・天然ガス(13A)用


○四割

○ねじサイズ M6 × P1.0

○材質 BsBM+Cu(真鍮+銅)

○全長 29mm

○六角対辺 9mm

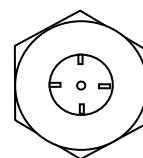

※EA300M,MB,MD,EA300-1,EA300M-4等