

EA304AH-1 (半田ごて)

※EA304AF,AG,AHの交換用




消費電力	70W(24V)
こて先 アース間抵抗	<2Ω
リーク電圧	<2mV
サイズ (除コード)	188mm (EA304AH-22装着時)
重量 (除コード)	30g (EA304AH-22装着時)
コード	1.2m


- スリーブをロック式にすることにより、しっかり固定できます。
- 静電気対策品

※こて先別売り(EA304AG-1~-38よりお選びください)


◆別売りこて先

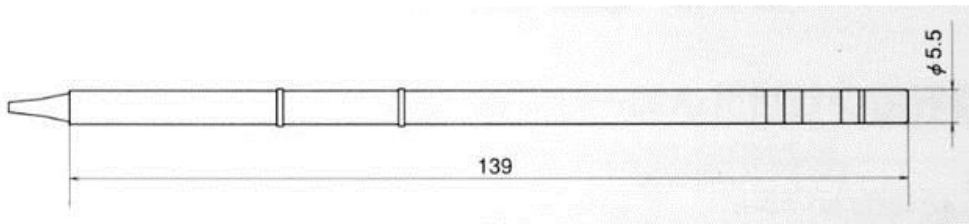


— : 廃番商品

 


EA304AG-1

 


EA304AG-2

 


EA304AG-3

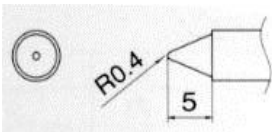


~~EA304AG-4~~

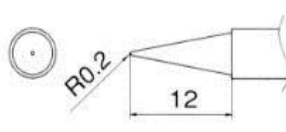


EA304AG-5

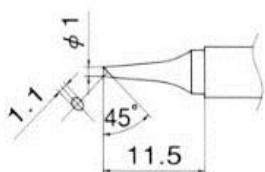


EA304AG-6

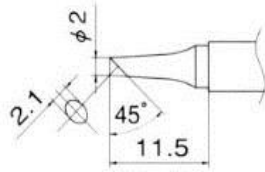


EA304AG-7

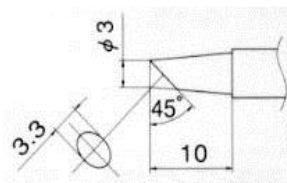


EA304AG-8

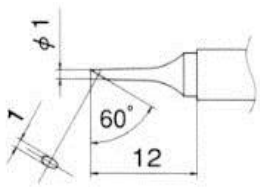


EA304AG-9

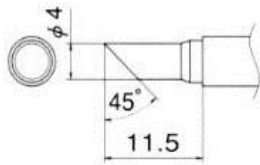


EA304AG-10

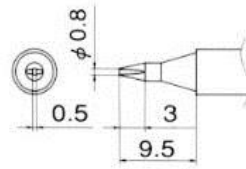


~~EA304AG-11~~

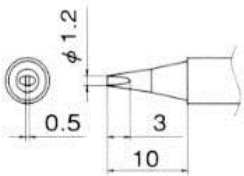


EA304AG-12

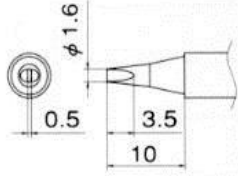


~~EA304AG-13~~

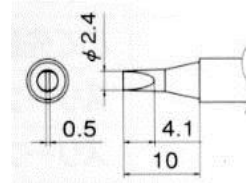


EA304AG-14

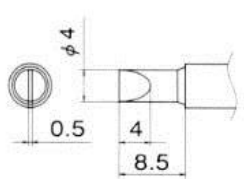


EA304AG-15

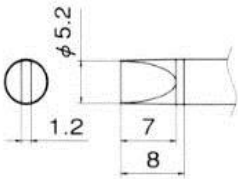


~~EA304AG-16~~

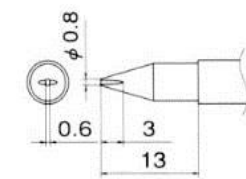


~~EA304AG-17~~

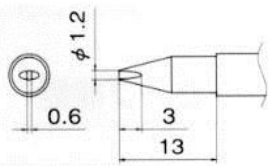


~~EA304AG-18~~

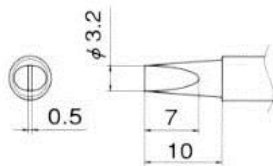


EA304AG-19

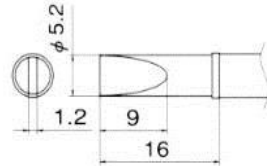


EA304AG-20

 


EA304AG-21

 


EA304AG-22

 


EA304AG-23

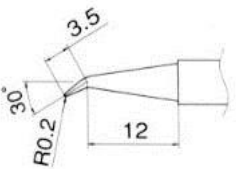


~~EA304AG-24~~

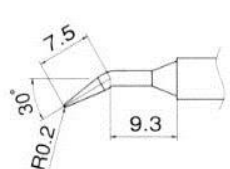


~~EA304AG-25~~

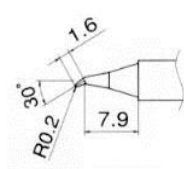


~~EA304AG-26~~

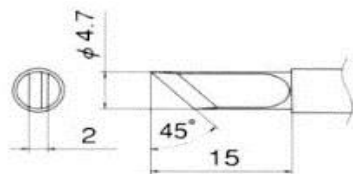


EA304AG-27

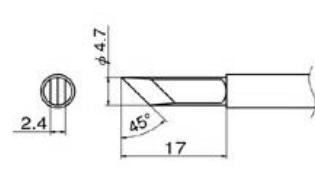


EA307AG-28

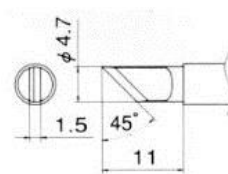


~~EA304AG-29~~

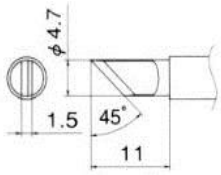


~~EA304AG-30~~

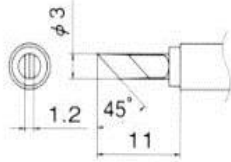


EA304AG-31

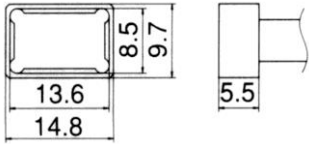


~~EA304AG-32~~

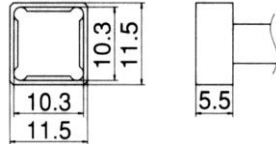


~~EA304AG-33~~

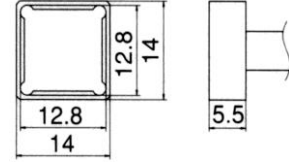


~~EA304AG-34~~

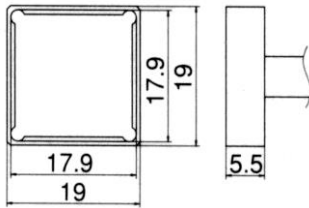


~~EA304AG-35~~

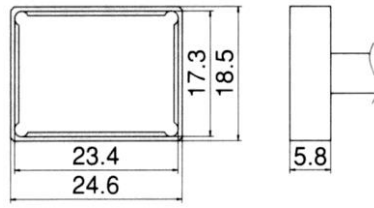

~~EA304AG-36~~

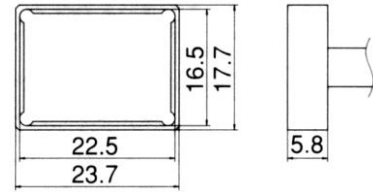

~~EA304AG-37~~

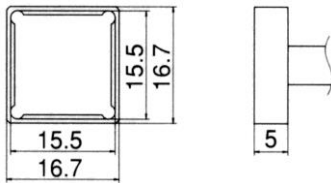

EA304AG-38