



# 軟質ガスケット寸法表

## ●軟質ガスケット/内パッキン(RFタイプ)

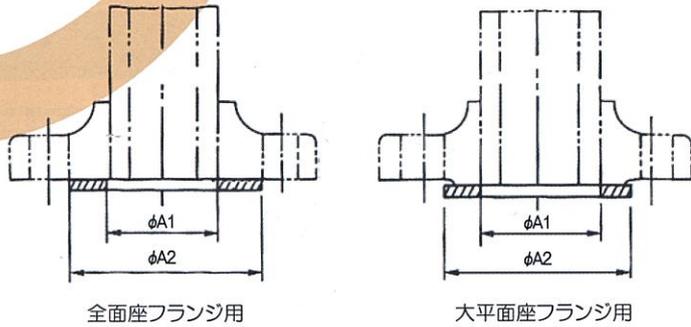

JIS B 2404-2206 管フランジ用ガスケット寸法からの適用となります。

## ●ユニオンガスケット

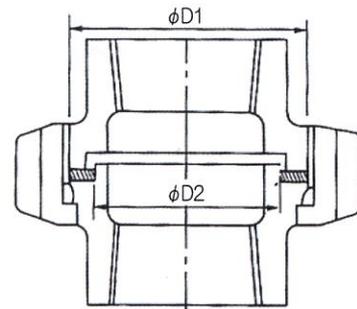


JIS B 2301 ねじ込み式可鍛鉄製管継手のF形寸法より設定した物です。

EA351CL  
-10  
-15  
-20  
-25  
-32  
-40  
-50  
-65  
-80  
-100  
-125  
-150

フランジ 呼び径	内径 φA1	ガスケット外径 φA2					ユニオン 呼び径	内径 φD1	外径 φD2
		2K	5K	10K	16K	20K			
10A	18	-	45	53	53	53	6A	13	18
15A	22	-	50	58	58	58	8A	17	23
20A	28	-	55	63	63	63	10A	21	28
25A	35	-	65	74	74	74	15A	25	32
32A	43	-	78	84	84	84	20A	31	39
40A	49	-	83	89	89	89	25A	39	48
50A	61	-	93	104	104	104	32A	47	57
65A	84	-	118	124	124	124	40A	54	64
80A	90	-	129	134	140	140	50A	66	78
90A	102	-	139	144	150	150	65A	82	96
100A	115	-	149	159	165	165	80A	96	111
125A	141	-	184	190	203	203	90A	109	126
150A	167	-	214	220	238	238	100A	122	141
175A	192	-	240	245	-	-	125A	151	170
200A	218	-	260	270	283	283	150A	178	200
225A	244	-	285	290	-	-			
250A	270	-	325	333	356	356			
300A	321	-	370	378	406	406			
350A	359	-	413	423	450	450			
400A	410	-	473	486	510	510			
450A	460	535	533	541	575	575			
500A	513	585	583	596	630	630			
550A	564	643	641	650	684	684			
600A	615	693	691	700	734	734			
650A	667	748	746	750	784	805			
700A	718	798	796	810	836	855			
750A	770	856	850	870	896	918			
800A	820	906	900	920	945	978			
850A	872	956	950	970	995	1,038			
900A	923	1,006	1,000	1,020	1,045	1,088			
1000A	1,025	1,106	1,100	1,124	1,158	-			
1100A	1,130	1,216	1,210	1,234	1,258	-			
1200A	1,230	1,326	1,320	1,344	1,368	-			
1300A	1,335	-	-	-	1,474	-			
1350A	1,385	1,481	1,475	1,498	1,534	-			
1400A	1,435	-	-	-	1,584	-			
1500A	1,540	1,636	1,630	1,658	1,694	-			

●軟質ガスケット 全面形パッキン(FFタイプ)

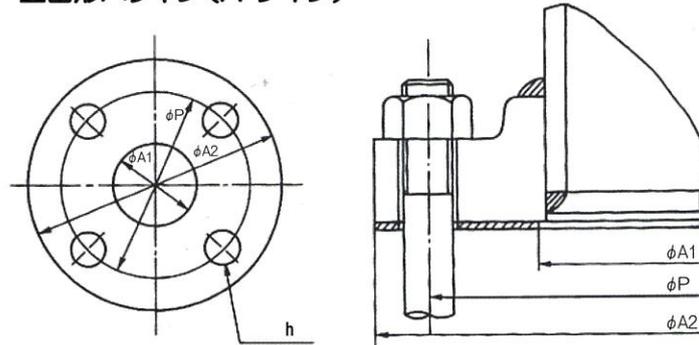

JIS B 2404-2206 管フランジ用ガスケット寸法からの適用となります。

フランジ	内径	2K			5K			10K			16K				
		呼び径	$\phi A1$	外径 $\phi A2$	PCD $\phi P$	$n \times h$	外径 $\phi A2$	PCD $\phi P$	$n \times h$	外径 $\phi A2$	PCD $\phi P$	$n \times h$	外径 $\phi A2$	PCD $\phi P$	$n \times h$
EA351CL	-10	10A	18	-	-	-	75	55	4X12	90	65	4X15	90	65	4X15
	-15	15A	22	-	-	-	80	60	4X12	95	70	4X15	95	70	4X15
	-20	20A	28	-	-	-	85	65	4X12	100	75	4X15	100	75	4X15
	-25	25A	35	-	-	-	95	75	4X12	125	90	4X19	125	90	4X19
	-32	32A	43	-	-	-	115	90	4X15	135	100	4X19	135	100	4X19
	-40	40A	49	-	-	-	120	95	4X15	140	105	4X19	140	105	4X19
	-50	50A	61	-	-	-	130	105	4X15	155	120	4X19	155	120	8X19
	-65	65A	84	-	-	-	155	130	4X15	175	140	4X19	175	140	8X19
	-80	80A	90	-	-	-	180	145	4X19	185	150	8X19	200	160	8X23
		90A	102	-	-	-	190	155	4X19	195	160	8X19	210	170	8X23
	-100	100A	115	-	-	-	200	165	8X19	210	175	8X19	225	185	8X23
	-125	125A	141	-	-	-	235	200	8X19	250	210	8X23	270	225	8X25
	-150	150A	167	-	-	-	265	230	8X19	280	240	8X23	305	260	12X25
		175A	192	-	-	-	300	260	8X23	305	265	12X23	-	-	-
		200A	218	-	-	-	320	280	8X23	330	290	12X23	350	305	12X25
		225A	244	-	-	-	345	305	12X23	350	310	12X23	-	-	-
		250A	270	-	-	-	385	345	12X23	400	355	12X25	430	380	12X27
		300A	321	-	-	-	430	390	12X23	445	400	16X25	480	430	16X27
		350A	359	-	-	-	480	435	12X25	490	445	16X25	540	480	16X33
		400A	410	-	-	-	540	495	16X25	560	510	16X27	605	540	16X33
		450A	460	605	555	16X23	605	555	16X25	620	565	20X27	675	605	20X33
		500A	513	655	605	20X23	655	605	20X25	675	620	20X27	730	660	20X33
		550A	564	720	665	20X25	720	665	20X27	745	680	20X33	795	720	20X39
		600A	615	770	715	20X25	770	715	20X27	795	730	24X33	845	770	24X39
		650A	667	825	770	24X25	825	770	24X27	845	780	24X33	-	-	-
		700A	718	875	820	24X25	875	820	24X27	905	840	24X33	-	-	-
		750A	770	945	880	24X27	945	880	24X33	970	900	24X33	-	-	-
		800A	820	995	930	24X27	995	930	24X33	1,020	950	28X33	-	-	-
		850A	872	1,045	980	24X27	1,045	980	24X33	1,070	1,000	28X33	-	-	-
		900A	923	1,095	1,030	24X27	1,095	1,030	24X33	1,120	1,050	28X33	-	-	-
		1000A	1,025	1,195	1,130	28X27	1,195	1,130	28X33	1,235	1,160	28X39	-	-	-
		1100A	1,130	1,305	1,240	28X27	1,305	1,240	28X33	1,345	1,270	28X39	-	-	-
		1200A	1,230	1,420	1,350	32X27	1,420	1,350	32X33	1,465	1,380	32X39	-	-	-
		1300A	1,335	-	-	-	-	-	-	-	-	-	-	-	-
		1350A	1,385	1,575	1,505	32X27	1,575	1,505	32X33	1,630	1,540	36X45	-	-	-
		1400A	1,435	-	-	-	-	-	-	-	-	-	-	-	-
		1500A	1,540	1,730	1,660	36X27	1,730	1,660	36X33	1,795	1,700	40X45	-	-	-