


EA423MW-8~-24 シールワッシャー

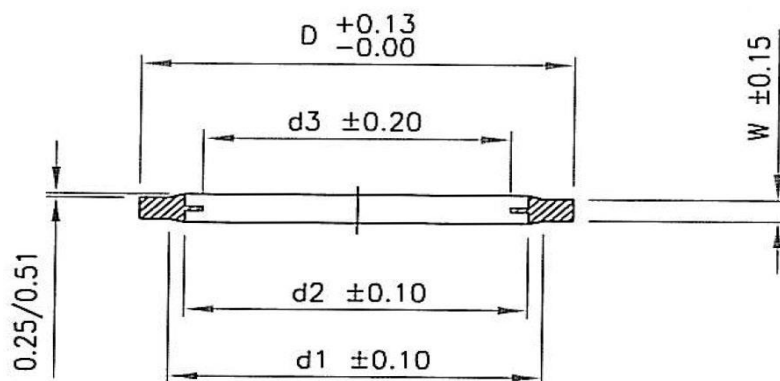

品番	ボルト	D	d1	d2	d3	W	h
EA423MW-8	M8	14.00	10.40	8.70	6.40	1.00	0.30
EA423MW-10	M10	16.00	12.40	10.70	8.05	1.50	0.40
EA423MW-12	M12	18.00	14.30	12.70	9.73	1.50	0.40
EA423MW-16	M16	24.00	18.40	16.70	13.41	1.50	0.40
EA423MW-18	M18	26.00	20.40	18.70	14.76	1.50	0.40
EA423MW-22	M22	30.00	24.40	22.70	18.74	2.00	0.40
EA423MW-24	M24	32.00	26.40	24.70	20.11	2.00	0.40

○材質…ニトリルゴム
(ニトリルゴムの周りの金属:鉄)

○10個入り