


EA425CF-41~104 エルボユニオン

特長:耐蝕性・耐薬品性に優れています。

高温・高圧に対応

あらゆる分野に使用出来ます。

(単位: mm)

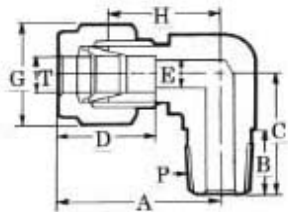

品番	適用パイプ外径T	P (PT)	A	B	C	D	E	G (HEX)	H
EA425CF-41	4	1/8	27.8	11	22	15.3	3.5	14	20.5
EA425CF-42	4	1/4	27.8	13	24	15.3	3.5	14	20.5
EA425CF-61	6	1/8	27.9	11	22	15.4	5	14	20.5
EA425CF-62	6	1/4	27.9	13	24	15.4	5	14	20.5
EA425CF-63	6	3/8	28.9	14	27	15.4	5	14	21.5
EA425CF-82	8	1/4	28.8	13	24	16.8	6	15.87	21
EA425CF-83	8	3/8	29.8	14	27	16.8	6	15.87	22
EA425CF-84	8	1/2	31.8	17	35	16.8	6	15.87	24
EA425CF-102	10	1/4	30.8	13	27	17.8	7	19	23
EA425CF-103	10	3/8	30.8	14	27	17.8	8	19	23
EA425CF-104	10	1/2	32.8	17	35	17.8	8	19	25

廃番

廃番