
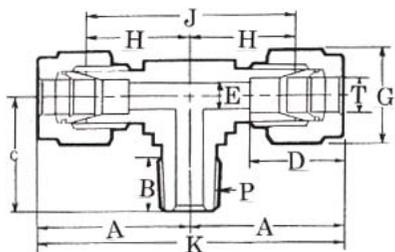


EA425CL-41~102 両口チーズユニオン

特長: 耐蝕性・耐薬品性に優れています。

高温・高圧に対応

あらゆる分野に使用出来ます。

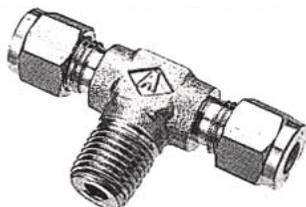

(単位:mm)

品番	適用パイプ外径T	P (PT)	A	B	C	D	E	G (HEX)	H	J	K
EA425CL-41	4	1/8	27.8	11	22	15.3	3.5	14	20.5	41	55.6
EA425CL-61	6	1/8	27.9	11	21	15.4	5	14	20.5	41	55.8
EA425CL-62	6	1/4	28.9	13	23	15.4	5	14	21.5	43	57.8
EA425CL-81	8	1/8	29.8	11	22	16.8	5	15.87	22	44	59.6
EA425CL-82	8	1/4	29.8	13	23	16.8	6	15.87	22	44	59.6
EA425CL-102	10	1/4	30.8	13	25	17.8	7	19	23	46	61.6

廃番

廃番