


EA425CN-41~104 圧力計ユニオン

特長: 耐蝕性・耐薬品性に優れています。

高温・高圧に対応

あらゆる分野に使用出来ます。

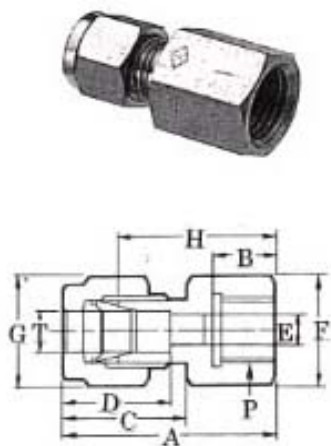

(単位: mm)

品番	適用パイプ外径T	G (PF)	A	B	C	D	E	F (HEX)	G (HEX)	H	
EA425CN-41	4	1/8	34.8	12	17.8	15.3	3.5	14	14	27.5	廃番
EA425CN-42	4	1/4	35.8	15	17.8	15.3	3.5	17	14	28.5	廃番
EA425CN-61	6	1/8	34.9	12	17.9	15.4	5	14	14	27.5	
EA425CN-62	6	1/4	35.9	15	17.9	15.4	5	17	14	28.5	
EA425CN-63	6	3/8	37.9	16	17.9	15.4	5	22	14	30.5	
EA425CN-82	8	1/4	36.8	15	18.8	16.8	6	17	15.87	29	
EA425CN-83	8	3/8	38.8	16	18.8	16.8	6	22	15.87	31	
EA425CN-84	8	1/2	40.8	17	18.8	16.8	6	26	15.87	33	廃番
EA425CN-102	10	1/4	37.8	15	19.8	17.8	6	17	19	30	
EA425CN-103	10	3/8	39.8	16	19.8	17.8	6	22	19	32	
EA425CN-104	10	1/2	41.8	17	19.8	17.8	8	26	19	34	廃番