


付属部品

アダプター


部品番号	B	C	D	H1	H2	R(PT) G(PF)	L	概略 重量g
6-0404	17.5	13	5.5	19	19	1/4	38.5	50
6-0606	19	15	7.0	22	22	3/8	42	85
6-0808	22	18	10.0	27	27	1/2	50	115
6-1212	24.5	20	16.0	36	36	3/4	56.5	230
6-1616	27	22	21.5	41	41	1	61	315
6-2020	31	25	27.5	50	50	1 1/4	70	545
6-2424	34	25	33.0	60	60	1 1/2	73	790
6-3232	37	30	44.0	70	70	2	84	1160

PART NO.6

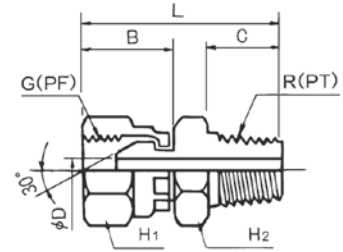


部品番号	A	B	C	D	H	R(PT) G(PF)	L	概略 重量g
7-0404	9.5	13	13	5.5	19	1/4	30	25
7-0606	12.5	15	15	7.0	22	3/8	34	50
7-0808	16.0	18	18	10.0	27	1/2	40	55
7-1212	21.5	20	20	16.2	36	3/4	45	150
7-1616	27.5	22	22	21.5	41	1	49	190
7-2020	36.0	24	25	27.5	50	1 1/4	54	310
7-2424	42.0	24	25	33.0	60	1 1/2	54	385
7-3232	54.0	28	30	44.0	70	2	64	600

PART NO.7

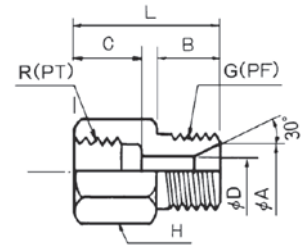

部品番号	B	C	D	H1	H2	R(PT) G(PF)	L	概略 重量g	
8-0404	EA425GG-2	17.5	13	5.5	19	19	1/4	34.5	40
8-0606	EA425GG-3	19	15	7.0	22	19	3/8	38	70
8-0808	EA425GG-4	21	18.5	10.0	27	27	1/2	43	105
8-1212	EA425GG-6	24	20	16.5	36	36	3/4	49	170
8-1616	EA425GG-8	26	22	21.5	41	41	1	53	290
8-2020		30	25	27.5	50	50	1 1/4	60	450
8-2424		33	25	33.0	60	60	1 1/2	63	620
8-3232		35	30	44.0	70	70	2	71	750

PART NO.8

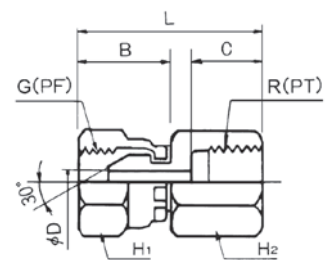

部品番号	B	D	H	H1	H2	G(PF)	L	概略 重量g
9-0404	17	5.5	19	19	19	1/4	42	60
9-0606	19	7.0	22	22	22	3/8	46	105
9-0808	22	10.0	27	27	27	1/2	54	130
9-1212	24	16.0	36	36	36	3/4	60	285
9-1616	27	21.5	41	41	41	1	66	375
9-2020	30	27.5	50	50	50	1 1/4	74	660
9-2424	33	33.0	60	60	60	1 1/2	80	950
9-3232	36	44.0	70	70	70	2	89	1390

PART NO.9

