


PU

ユニオン

Union

黄銅製

Brass

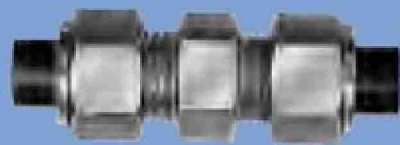

ミリ系列/METRIC SERIES

部品番号 PART NO.	適用チューブ TUBE SIZE TO BE USED 外径×内径 O.D. (mm)×I.D. (mm)	φd (mm)	L ₁ (mm)	二面幅 TWO FACE WIDTH (mm)		重量 WEIGHT (g)	有効断面積 EFFECTIVE SECTIONAL AREA (mm ²)
				S ₁	S ₂		
PU- 4×3 -BS	4×3	2.0	27	10	10	14	2.1
PU- 6×4.5-BS	6×4.5	3.5	29	12	12	19	7.5
PU- 8×6 -BS	8×6	5.0	30	14	14	25	18.0
PU-10×7.5-BS	10×7.5	6.5	33	17	17	39	31.0
PU-12×9 -BS	12×9	8.0	35	19	19	51	47.0
PU- 4×2.5-BS	4×2.5	1.5	27	10	10	14	1.6
PU- 6×4 -BS	6×4	3.0	29	12	12	19	7.2
PU- 8×5 -BS	8×5	4.0	30	14	14	25	11.0
PU-10×6.5-BS	10×6.5	5.5	33	17	17	39	21.0
PU-12×8 -BS	12×8	7.0	35	19	19	51	35.0

EA425LC-6

EA425LC-8

EA425LC-10

インチ系列/INCH SERIES

部品番号 PART NO.	適用チューブ TUBE SIZE TO BE USED 外径×内径 O.D. (mm)×I.D. (mm)	φd (mm)	L ₁ (mm)	二面幅 TWO FACE WIDTH (mm)		重量 WEIGHT (g)	有効断面積 EFFECTIVE SECTIONAL AREA (mm ²)
				S ₁	S ₂		
PU-1/ 8-BS	3.18×2.36	1.4	27	8	8	9	2.0
PU-3/16-BS	4.76×3.48	2.5	27	10	10	13	4.0
PU-1/ 4-BS	6.35×4.57	3.6	29	12	12	19	9.0
PU-5/16-BS	7.94×5.90	4.9	30	14	14	25	19.0
PU-3/ 8-BS	9.53×6.99	6.0	32	17	17	39	28.0
PU-1/ 2-BS	12.70×9.56	8.6	36	19	19	48	47.0

