




ユニオン

RoHS対応

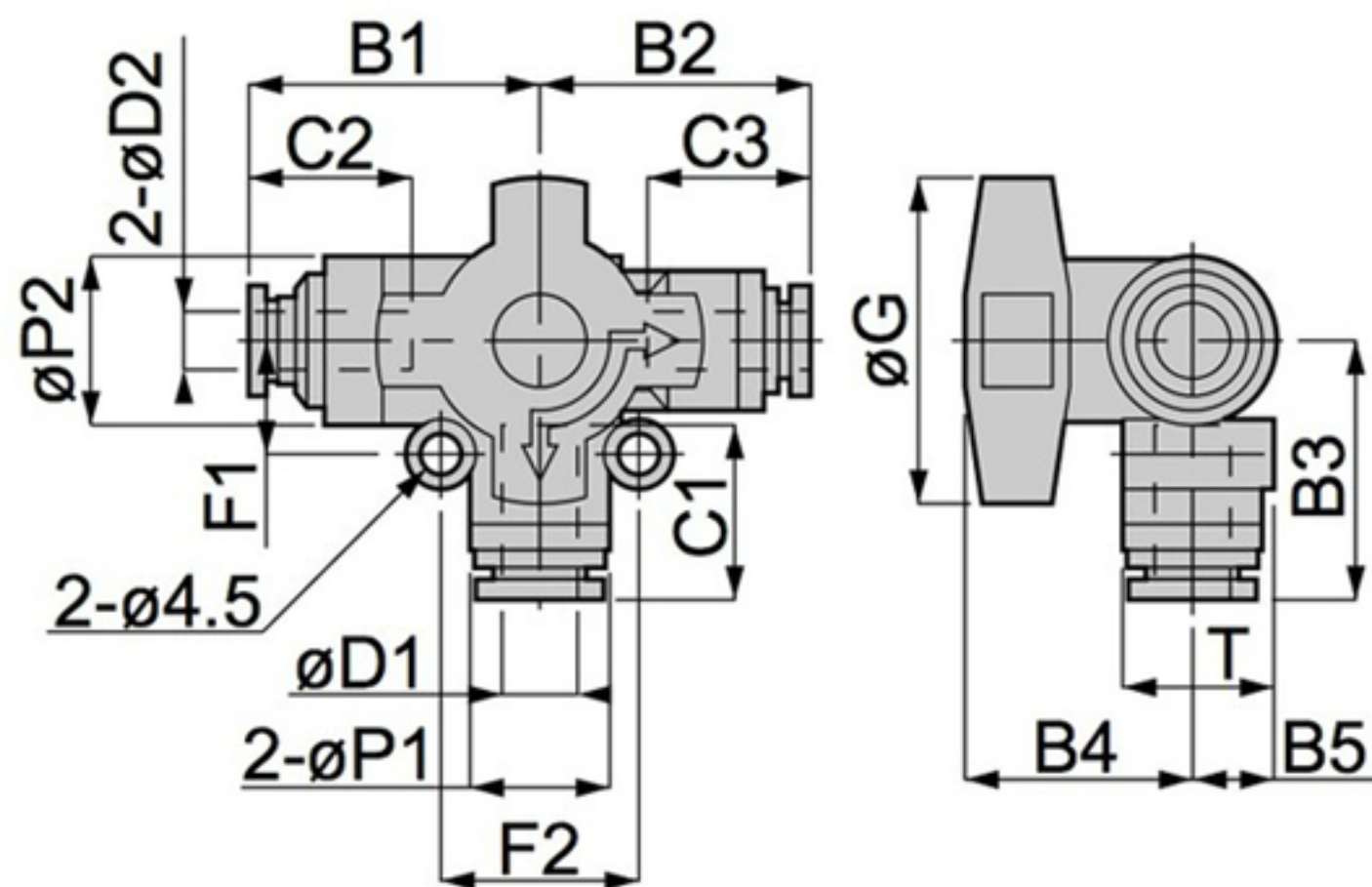

	形 式	チーブ外径 øD1	チーブ外径 øD2	チーブ径 C1	チーブ径 C2	チーブ径 C3	B1	B2	B3	B4	B5	T	F1	F2	øP1	øP2	øG	有効断面積 (mm ²)	質量 (g)
EA425SA-66	HBV6-6	6	6	16.9	17	16.9	26.9	28.8	27	23.8	8.9	16.2	12	20	14.5	17.8	34.5	9	50
EA425SA-86	HBV8-6	8	6	18.4	17	16.9	26.9	28.8	26.9	23.8	8.9	16.2	12	20	14.5	17.8	34.5	11	53
EA425SA-88	HBV8-8		8		18.2	18.4	28.5	28.7										17	50
EA425SA-110	HBV10-10	10	10	21.2	20.7	21.2	36.1	36.5	34.8	28.5	11.9	22.4	15	25	21	23.8	44	24	122