 



サドルバンド
(厚サドル/ボルト穴)

SGP管用

- ◇架台への固定可能
- ◇電気亜鉛めっき仕上げ

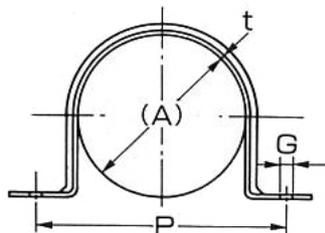

品番	径称	適合管外径	使用材料 板厚×幅	穴径G	P
EA440BA-15R	15A	21.7mm	2.3×24	φ11	50
EA440BA-20R	20A	27.2mm			57
EA440BA-25R	25A	34.0mm			63
EA440BA-32R	32A	42.7mm			72
EA440BA-40R	40A	48.6mm			77
EA440BA-50R	50A	60.5mm			90
EA440BA-65R	65A	76.3mm			113
EA440BA-80R	80A	89.1mm			125
EA440BA-100R	100A	114.3mm			150

- スチール製
- SGP管用
- 木ビス類も使用可能
- 電気亜鉛めっき仕上げ