


EA440CK-15 ~ -100 [ステンレス製]鋼管用防振立バンド

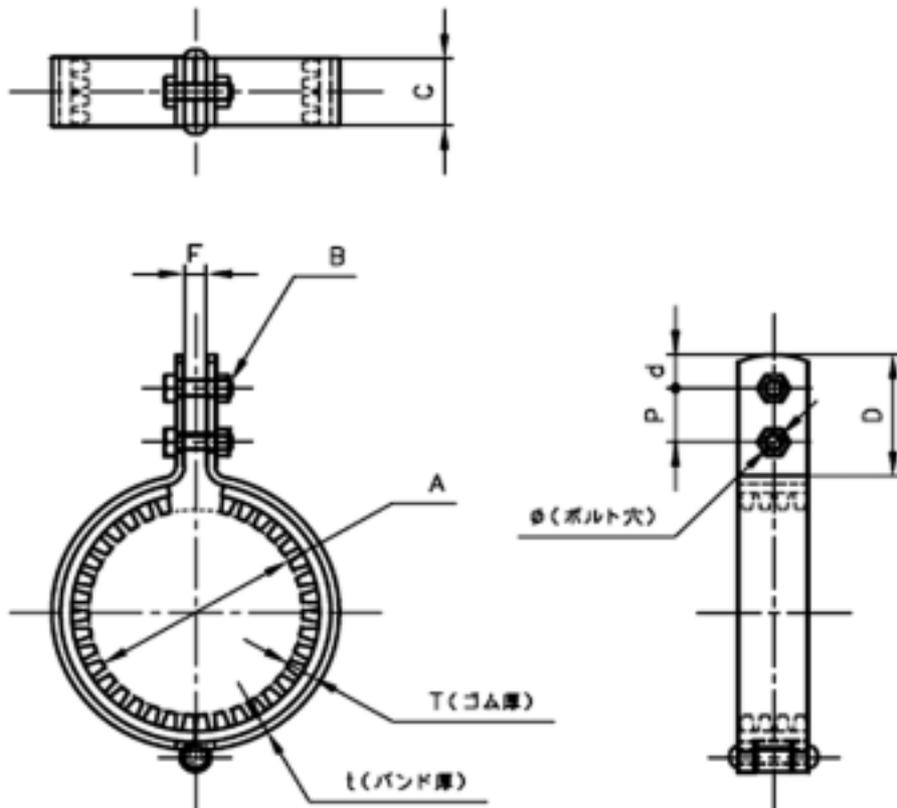

材質 …
ステンレス(SUS304)

SGP管用

10mmゴム付

品番	径称	適合管 外径(A)	使用ボルト サイズ(B)	C	D	d	F	P	ゴム 厚(T)	バンド 厚(t)	ボルト 穴()	重量 (g)
EA440CK-15	15A	21.7	M6 × 20	25	45	12.5	8	20	10	2	7	138.9
EA440CK-20	20A	27.2										139.8
EA440CK-25	25A	34.0										155.4
EA440CK-32	32A	42.7										168.3
EA440CK-40	40A	48.6										185.7
EA440CK-50	50A	60.5										209.2
EA440CK-65	65A	76.3								244.1		
EA440CK-80	80A	89.1								3		269.4
EA440CK-100	100A	114.3								354.6		

(サイズ単位:mm)