


**【品番】**

EA440KA-40B、KB-40B、KC-40B、KD-40B、  
EA440KE-40B、KF-40B、KG-40B、KH-40B、  
EA440KJ-40B、KK-40B、KL-40B、KM-40B、  
EA440KN-40B、KP-40B、KR-40B、KS-40B、  
EA440KT-40B、KW-40B、KX-40B、KY-40B、  
EA440KZ-40B



**【品名】**

**[ステンレス製]シムリング板厚セット**

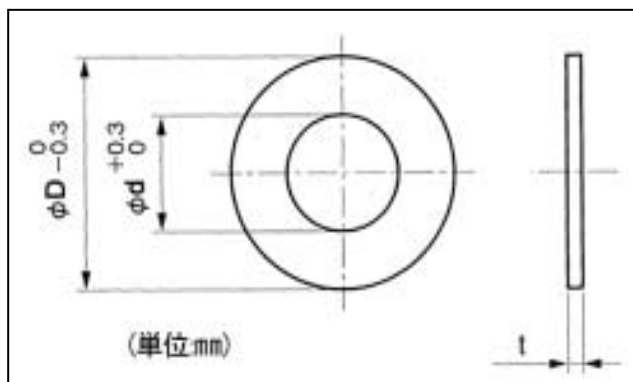

材 質 … ステンレス(SUS304)

セット内容 … 厚み(t) : 0.1・0.2・0.3・0.5mm各10枚

入 数 … 40枚

重 量 … 30g(40枚)

RoHS適合品

品番	サイズ(mm)	
	内径(d)	外径(D)
EA440KA-40B	3	6
EA440KB-40B		8
EA440KC-40B	4	8
EA440KD-40B		10
EA440KE-40B	5	10
EA440KF-40B		12
EA440KG-40B	6	12
EA440KH-40B		14
EA440KJ-40B	8	14
EA440KK-40B		16
EA440KL-40B	10	18
EA440KM-40B		20
EA440KN-40B	12	18
EA440KP-40B		20
EA440KR-40B	16	22
EA440KS-40B		24
EA440KT-40B	17	22
EA440KW-40B		24
EA440KX-40B	20	24
EA440KY-40B		28
EA440KZ-40B		30

**板厚公差**

板厚(mm)	0.1	0.2	0.3	0.5
公差(mm)	±0.008	±0.01	±0.015	±0.02