

**【品番】**

EA440XA-0.1 ~ -1、XB-0.1 ~ -1、XC-0.1 ~ -1、XD-0.1 ~ -1、  
EA440XE-0.1 ~ -1、XF-0.1 ~ -1、XG-0.1 ~ -1、XH-0.1 ~ -1、  
EA440XJ-0.1 ~ -1、XK-0.1 ~ -1

**【品名】**

**【スチール製】ベース用シム**




モーターベースなどの  
芯出し調整に



材 質 … スチール 「 SPCC (冷間圧延鋼板) 相当 」

RoHS適合品

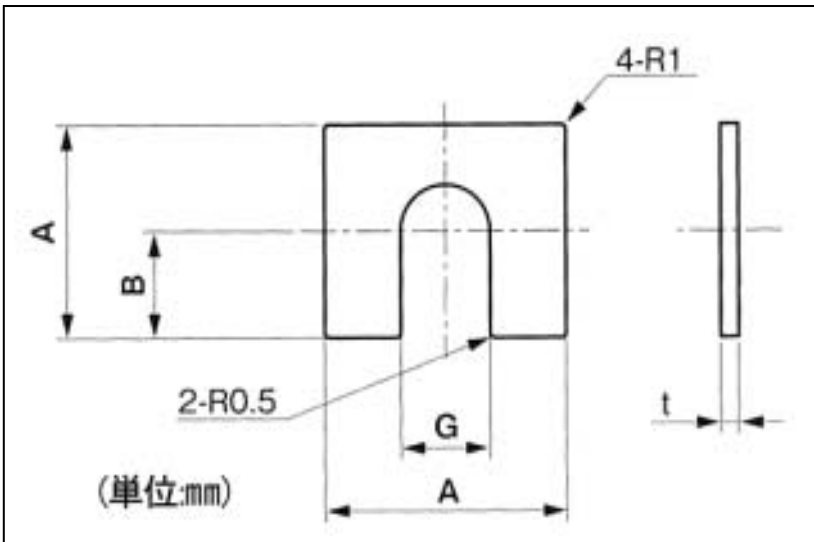

品番	サイズ (mm)				
	幅 (A)	溝幅 (G)	溝深さ (B)	厚み (t)	板厚公差
EA440XA-0.1	20	9	10	0.1	± 0.03
EA440XA-0.2				0.2	± 0.03
EA440XA-0.5				0.5	± 0.05
EA440XA-1				1.0	± 0.08
EA440XB-0.1	30	13	15	0.1	± 0.03
EA440XB-0.2				0.2	± 0.03
EA440XB-0.5				0.5	± 0.05
EA440XB-1				1.0	± 0.08
EA440XC-0.1	43	12	22	0.1	± 0.03
EA440XC-0.2				0.2	± 0.03
EA440XC-0.5				0.5	± 0.05
EA440XC-1				1.0	± 0.08
EA440XD-0.1	48	14	24	0.1	± 0.03
EA440XD-0.2				0.2	± 0.03
EA440XD-0.5				0.5	± 0.05
EA440XD-1				1.0	± 0.08
EA440XE-0.1	53	14	27	0.1	± 0.03
EA440XE-0.2				0.2	± 0.03
EA440XE-0.5				0.5	± 0.05
EA440XE-1				1.0	± 0.08
EA440XF-0.1	68	16	34	0.1	± 0.03
EA440XF-0.2				0.2	± 0.03
EA440XF-0.5				0.5	± 0.05
EA440XF-1				1.0	± 0.08
EA440XG-0.1	83	20	42	0.1	± 0.03
EA440XG-0.2				0.2	± 0.03
EA440XG-0.5				0.5	± 0.05
EA440XG-1				1.0	± 0.08
EA440XH-0.1	98	25	49	0.1	± 0.03
EA440XH-0.2				0.2	± 0.03
EA440XH-0.5				0.5	± 0.05
EA440XH-1				1.0	± 0.08
EA440XJ-0.1	118	30	54	0.1	± 0.03
EA440XJ-0.2				0.2	± 0.03
EA440XJ-0.5				0.5	± 0.05
EA440XJ-1				1.0	± 0.08
EA440XK-0.1	200	36	100	0.1	± 0.03
EA440XK-0.2				0.2	± 0.03
EA440XK-0.5				0.5	± 0.05
EA440XK-1				1.0	± 0.08