

【品番】

EA440YA-0.05 ~ -1、YB-0.05 ~ -1、YC-0.05 ~ -1、YD-0.05 ~ -1、
EA440YE-0.05 ~ -1、YF-0.05 ~ -1、YG-0.05 ~ -1、YH-0.05 ~ -1、
EA440YJ-0.05 ~ -1、YK-0.05 ~ -1


【品名】

[ステンレス製]ベース用シム



材質 … ステンレス(SUS304)

RoHS適合品

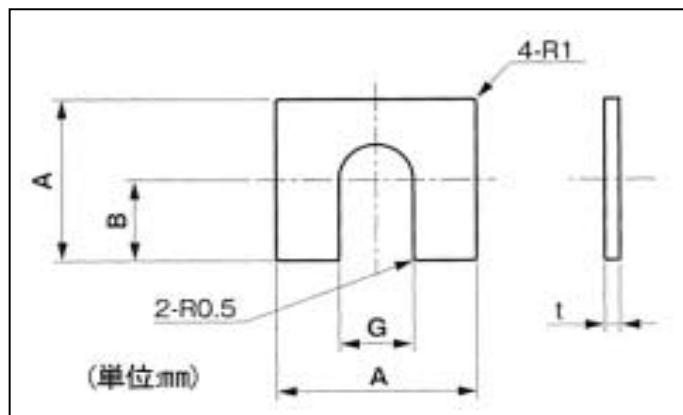

品番	サイズ(mm)				
	幅(A)	溝幅(G)	溝深さ(B)	厚み(t)	板厚公差
EA440YA-0.05	20	9	10	0.05	±0.005
EA440YA-0.1				0.1	±0.008
EA440YA-0.2				0.2	±0.01
EA440YA-0.5				0.5	±0.02
EA440YA-1				1.0	±0.035
EA440YB-0.05	30	13	15	0.05	±0.005
EA440YB-0.1				0.1	±0.008
EA440YB-0.2				0.2	±0.01
EA440YB-0.5				0.5	±0.02
EA440YB-1				1.0	±0.035

品番	サイズ(mm)				
	幅(A)	溝幅(G)	溝深さ(B)	厚み(t)	板厚公差
EA440YC-0.05	43	12	22	0.05	±0.005
EA440YC-0.1				0.1	±0.008
EA440YC-0.2				0.2	±0.01
EA440YC-0.5				0.5	±0.02
EA440YC-1				1.0	±0.035
EA440YD-0.05	48	14	24	0.05	±0.005
EA440YD-0.1				0.1	±0.008
EA440YD-0.2				0.2	±0.01
EA440YD-0.5				0.5	±0.02
EA440YD-1				1.0	±0.035
EA440YE-0.05	53	14	27	0.05	±0.005
EA440YE-0.1				0.1	±0.008
EA440YE-0.2				0.2	±0.01
EA440YE-0.5				0.5	±0.02
EA440YE-1				1.0	±0.035
EA440YF-0.05	68	16	34	0.05	±0.005
EA440YF-0.1				0.1	±0.008
EA440YF-0.2				0.2	±0.01
EA440YF-0.5				0.5	±0.02
EA440YF-1				1.0	±0.035
EA440YG-0.05	83	20	42	0.05	±0.005
EA440YG-0.1				0.1	±0.008
EA440YG-0.2				0.2	±0.01
EA440YG-0.5				0.5	±0.02
EA440YG-1				1.0	±0.035
EA440YH-0.05	98	25	49	0.05	±0.005
EA440YH-0.1				0.1	±0.008
EA440YH-0.2				0.2	±0.01
EA440YH-0.5				0.5	±0.02
EA440YH-1				1.0	±0.035
EA440YJ-0.05	118	30	54	0.05	±0.005
EA440YJ-0.1				0.1	±0.008
EA440YJ-0.2				0.2	±0.01
EA440YJ-0.5				0.5	±0.02
EA440YJ-1				1.0	±0.035
EA440YK-0.05	200	36	100	0.05	±0.005
EA440YK-0.1				0.1	±0.008
EA440YK-0.2				0.2	±0.01
EA440YK-0.5				0.5	±0.02
EA440YK-1				1.0	±0.035