


EA442AA-112~-145 フレアジョイント(冷凍空調用)

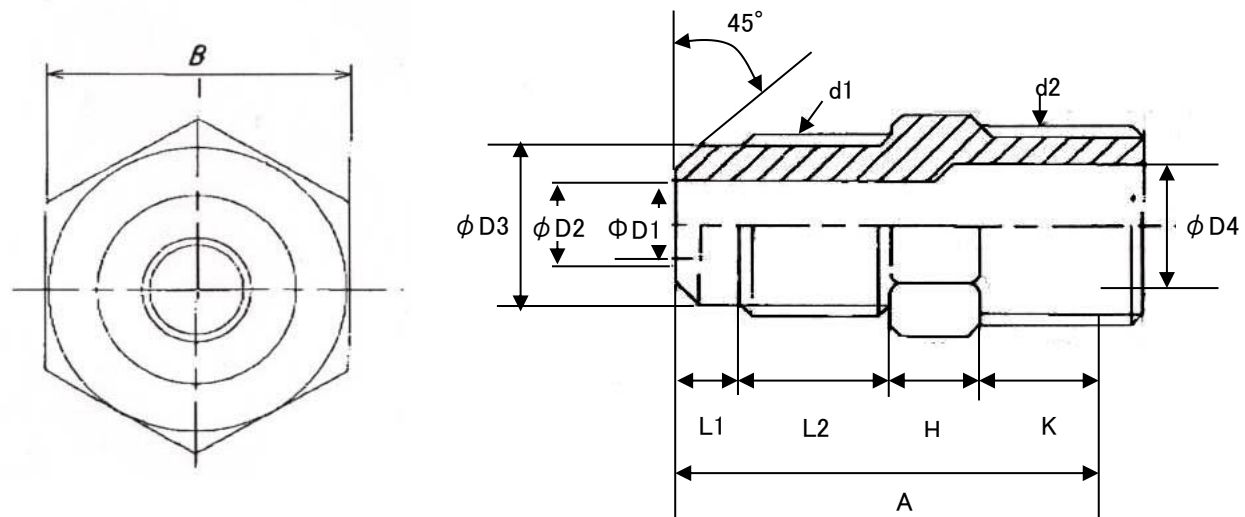

| 品番 | B | A | +0.2 -0.5 | L1 | L2 | H | K | D1 | D2 | D3 | D4 | d2 | d1 |
|-------------|----|------|--------------|-----|------|-----|----|----|------|------|----|--------|-------------|
| EA442AA-112 | 12 | 29.5 | | 3.5 | 10.5 | 5.5 | 10 | 5 | 6 | 8.8 | 5 | PT1/8" | UNF 7/16×20 |
| EA442AA-122 | 14 | 30.5 | | 3.5 | 10.5 | 5.5 | 11 | 5 | 6 | 8.8 | 5 | PT1/4" | UNF 7/16×20 |
| EA442AA-123 | 17 | 35 | | 4.5 | 12 | 7.5 | 11 | 8 | 8.5 | 13.2 | 5 | PT1/4" | UNF 5/8×18 |
| EA442AA-132 | 17 | 34.5 | | 3.5 | 10.5 | 7.5 | 13 | 5 | 6 | 8.8 | 8 | PT3/8" | UNF 7/16×20 |
| EA442AA-133 | 17 | 37.5 | | 4.5 | 12 | 7.5 | 13 | 8 | 8.5 | 13.2 | 8 | PT3/8" | UNF 5/8×18 |
| EA442AA-134 | 21 | 41 | | 5 | 15 | 8 | 13 | 10 | 11.2 | 16.5 | 8 | PT3/8" | UNF 3/4×16 |
| EA442AA-142 | 21 | 41 | | 3.5 | 10.5 | 9.5 | 18 | 5 | 6 | 8.8 | 13 | PT1/2" | UNF 7/16×20 |
| EA442AA-143 | 21 | 43.5 | | 4.5 | 12 | 9.5 | 18 | 8 | 8.5 | 13.2 | 13 | PT1/2" | UNF 5/8×18 |
| EA442AA-144 | 21 | 46.5 | | 5 | 15 | 9.5 | 18 | 10 | 11.2 | 16.5 | 13 | PT1/2" | UNF 3/4×16 |
| EA442AA-145 | 23 | 50 | | 5.5 | 16.5 | 10 | 18 | 13 | 14.5 | 19.2 | 13 | PT1/2" | UNF 7/8×14 |