

Hexagon Ball Valves

- Miniature ball valves made of brass nickel-plated
- For pneumatic or water installations in industry, construction or civil applications

Materials


- Body: Brass MS 58 nickel-plated
- Ball: Brass MS 58 chromed
- Ball seals: PTFE
- Handle: Plastic

Max. Working Pressure	Temperature	Thread	Media	
PN 10 bar	-10°C – +90°C	ISO 228	Air / Water	10

EA470M

Hexagon Ball Valves with 2 x female thread


	Thread connection	L	SW	H	Passage	Weight	Type No.
-2	2 x G 1/4 f	36	19	38	5.5	71	KM 14 TS
-3	2 x G 3/8 f	41	21	38	8	86	KM 38 TS
-4	2 x G 1/2 f	48	25	42	10	137	KM 12 TS

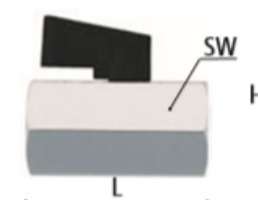

EA470MA

Hexagon Ball Valves with female/male thread

	Thread connection	L	SW	H	Passage	Weight	Type No.
-2	G 1/4 m - G 1/4 f	36	19	38	5.5	61	KMZ 14 TS
-3	G 3/8 m - G 3/8 f	41	21	38	8	83	KMZ 38 TS
-4	G 1/2 m - G 1/2 f	48	25	42	10	130	KMZ 12 TS

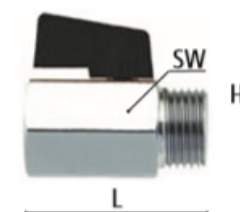

BALL VALVES

LUDECKE 395