

径違いソケット

略号: **RS**

硬質ポリ塩化ビニル管継手(JIS K6743)

型番	TS	T	N	U	SO	J	N	呼び径
	HITS	T	N	I	SO	J	N	呼び径

最高許容圧力(静水圧・20℃)
TS・HITS 0.75MPa




TS U-PVC




HITS HI-PVC



呼び径 13mm~50mm

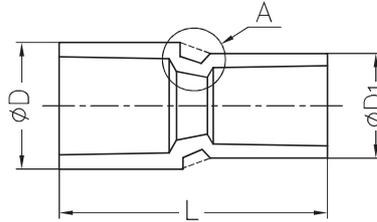

呼び径 65mm~150mm

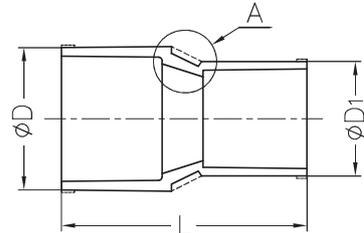

寸法表

(単位:mm)

呼び径	TS	HITS	D	t	D ₁	t ₁	L	呼び径	TS	HITS	D	t	D ₁	t ₁	L
16×13	○	○	29.0	3.5	24.0	3.0	61	50×20	○	○	70.0	5.0	33.0	3.5	116
20×13	○	○	33.0	3.5	24.0	3.0	68	50×25	○	○	70.0	5.0	40.0	4.0	140
EA471EG-1A 20×16	○	○	33.0	3.5	29.0	3.5	71	50×30	○	○	70.0	5.0	46.0	4.0	136
25×13	○	○	40.0	4.0	24.0	3.0	86	50×40	○	○	70.0	5.0	57.0	4.5	136
EA471EG-2A 25×16	○	○	40.0	4.0	29.0	3.5	85	▲ 65×40	○	○	87.0	6.6	57.0	4.5	145
EA471EG-3A 25×20	○	○	40.0	4.0	33.0	3.5	84	65×50	○	○	87.0	6.6	70.0	5.0	149
▲ 30×20	○	○	46.0	4.0	33.0	3.5	93	▲ 75×40	○	○	102.0	8.0	57.0	4.5	153
30×25	○	○	46.0	4.0	40.0	4.0	93	75×50	○	○	102.0	8.0	70.0	5.0	165
EA471EG-4A 40×20	○	○	57.0	4.5	33.0	3.5	113	75×65	○	○	102.0	8.0	87.0	6.6	159
40×25	○	○	57.0	4.5	40.0	4.0	114	100×75	○	○	130.0	10.0	102.0	8.0	190
40×30	○	○	57.0	4.5	46.0	4.0	114	125×100	○	○	157.0	11.0	130.0	10.0	229
								▲ 150×100	○	○	186.0	13.0	130.0	10.0	295
								150×125	○	○	186.0	13.0	157.0	11.0	272

(注) 1. Lの許容差は±4.0mmとします。 2. ▲は仕入品です。 3. ○はJIS K6743に準じています。