

径違いチーズ

略号: **T**

硬質ポリ塩化ビニル管継手 (JIS K6743)

型番 TS ▶ T N U TE J N 呼び径
HITS ▶ T N I TE J N 呼び径





TS
U-PVC

HITS
HI-PVC

呼び径13mm~50mm

呼び径65mm~150mm

最高許容圧力(静水圧・20℃)
TS・HITS 0.75MPa

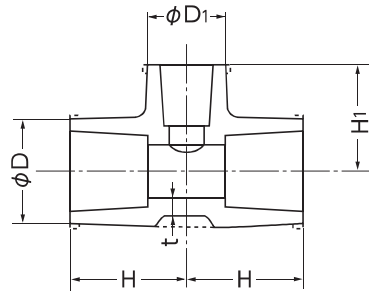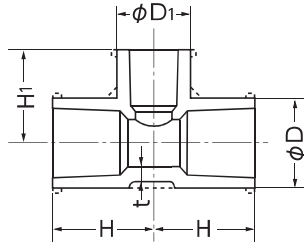

寸法表

(単位:mm)

呼び径	TS	HITS	D	t	H	D1	H1	呼び径	TS	HITS	D	t	H	D1	H1
16×13	○	○	29.0	3.5	41	24.0	38	40×13	○	○	57.0	4.5	66	24.0	52
EA471EH-1								▲ 40×16	○	○	57.0	4.5	68	29.0	57
20×13	○	○	33.0	3.5	46	24.0	40	40×20	○	○	57.0	4.5	70	33.0	62
EA471EH-2								40×25	○	○	57.0	4.5	73	40.0	67 EA471EH-6
EA471EH-3								40×30	○	○	57.0	4.5	76	46.0	71 EA471EH-7
25×13	○	○	40.0	4.0	51	24.0	43	50×13	○	○	70.0	5.0	74	24.0	58
EA471EH-4								50×16	○	○	70.0	5.0	76	29.0	63
EA471EH-5								50×20	○	○	70.0	5.0	78	33.0	68
25×16	○	○	40.0	4.0	53	29.0	48	50×25	○	○	70.0	5.0	81	40.0	73 EA471EH-8
EA471EH-11								50×30	○	○	70.0	5.0	84	46.0	77 EA471EH-9
25×20	○	○	40.0	4.0	55	33.0	53	50×40	○	○	70.0	5.0	90	57.0	88 EA471EH-10
EA471EH-12															
▲ 30×13	○	○	46.0	4.0	55	24.0	46								
65×40	○	○	87.0	6.6	100	57.0	95								
EA471EH-11															
30×16	○	○	46.0	4.0	57	29.0	51	100×50	○	○	130.0	10.0	125	70.0	122
EA471EH-12								100×75	○	○	130.0	10.0	140	102.0	132
30×20	○	○	46.0	4.0	59	33.0	56	125×75	○	○	157.0	11.0	160	102.0	147
EA471EH-12								125×100	○	○	157.0	11.0	173	130.0	167
30×25	○	○	46.0	4.0	62	40.0	61	150×75	○	○	186.0	13.0	195	102.0	158
								150×100	○	○	186.0	13.0	208	130.0	182
								150×125	○	○	186.0	13.0	217	157.0	201

(注) 1. H, H1の許容差は±0.1mmとします。 2. ▲は仕入品です。 3. ○はJIS K6743に準じています。