


EA475AJ-8~AJ-130 耐候性結束バンド



- 材質…ナイロン66
- 屋内外の紫外線の当たる場所でも使用可能。
- 使用温度…-40~85°C
- UL規格認定品

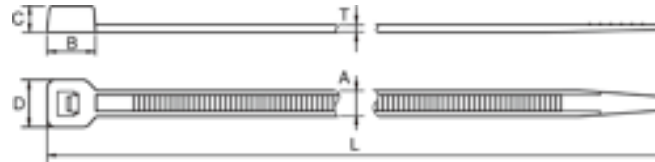

品番	結束径 φ (mm)	寸法 mm						ループ引張り強度(最小値) N(kgf)	入り数(本)	
		L	A	B	C	D	T			
EA475AJ-8	1.0~16	80	2.2	4.4	3.2	4.2	1	80(8.16)	100	
EA475AJ-10	1.0~22	100	2.5	4.8	3.5	4.8	1.1			
EA475AJ-15	1.0~36	152	3.5	5.9	4.4	6.1	1.2	135(13.77)		
EA475AJ-16	1.6~35	158	4.7	7.5	5.5	8.5	1.3	222.3(22.67)		廃番
EA475AJ-19	1.5~50	202	3.6	5.5	4	6.2	1.2	133.3(13.59)		
EA475AJ-20	1.5~50	202	4.6	7.3	5.9	7.6		255(22.94)		
EA475AJ-25	1.5~65	251						266.7(27.2)		
EA475AJ-27	2.0~70	270	4.8	9	5	8.8	1.5	222.3(22.67)		廃番
EA475AJ-30	1.5~80	301						266.7(27.2)		
EA475AJ-35	3.0~100	380	7.6	10.3	7.5	12.5	1.8	535(54.56)		50
EA475AJ-38	2.5~105	383	4.8	8.5	6	8.8	1.5	222.3(22.67)	100	
EA475AJ-45	15.0~130	460	7.6	10.6	7.6	12.5	1.8	535(54.56)	50	
EA475AJ-55	4.0~145	541	13	17	12	20	2	1109.9(113.2)	25	
EA475AJ-82	8.0~245	820	8.8	13	9.5	14	1.9	780(79.54)		
EA475AJ-100	152~330	1095	8.9	13.8			2.1			
EA475AJ-130	152~405	1325		14						