


PNEUMATIC TIRE SPREADER - portable high powered air pneumatic tire spreading device

model 20428 | 20428-LOB | 20428K




TIRE SPREADERS

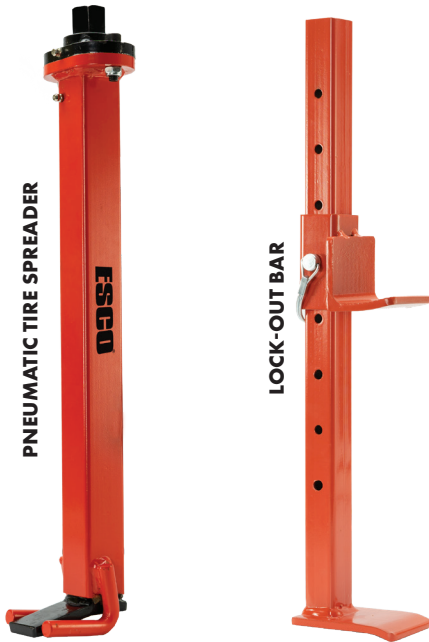

The **ESCO PNEUMATIC TIRE SPREADER SYSTEM** is a lightweight, portable solution for professional tire servicing, powered by any air, electric, or impact system. It uses pneumatic force to easily spread tires and pairs with the **MODEL 20428-LOB** lock-out bar for added safety, available together as the **MODEL 20428K KIT**. Designed for versatility, it accommodates a wide range of tire sizes, ensuring secure and efficient tire spreading.

- Patented pneumatic system engineered with ESCO's industry-leading design for longevity and performance.
- Portable design ideal for use in the field or shop, making tire servicing more efficient.
- Lightweight construction allows for easy transport and handling without sacrificing durability.
- Secure locking mechanism improves technician safety while keeping tires steady during service.
- Built to withstand the demands of commercial, agricultural, and OTR tire servicing applications.

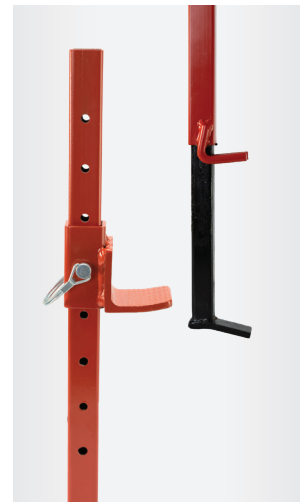

SPECIFICATIONS:	20428	20428-LOB	20428K
Material	Steel	Steel	Steel
Spreader Distance	0.5 - 13.5 in. 12.7 - 343 mm	NA	0.5 - 13.5 in. 12.7 - 343 mm
Lock-Out Positions	NA	(8) 2.5-13 in. 63.5 - 330 mm	(8) 2.5-13 in. 63.5 - 330 mm
Weight	11 lbs. 5 kg	3 lbs. 1.4 lbs.	15 lbs. 6.8 kg
Warranty	1-Year Warranty	1-Year Warranty	1-Year Warranty
UPC	816904025953	816904025960	816904025977