


型式	仕様	ストローク	加圧能力	シャンク寸法	重量	A	B	C	D	E	F
RP-35		35	200kg	10×30	9.5kg	250	292	185	77	175	30

EA525X-3A



ラック式プレス

RP-35
(ベース安定型)

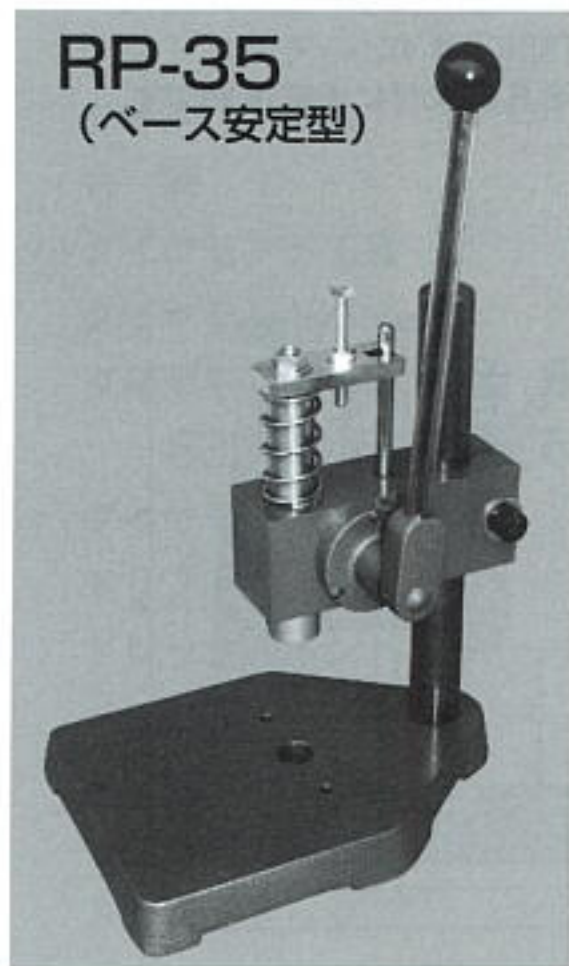

治具取付穴

