

BESSEY® C Clamps



CDF Series Drop Forged & 540 Series Ductile Alloy C-Clamps



Simply better.

Features & Benefits

- Drop forged and heat-treated for added strength
- Ball-in-swivel pad
- Available in two styles:
 - Copper coated to resist weld spatter
 - Black oxide to resist corrosion
- Large Acme threads for faster clamping

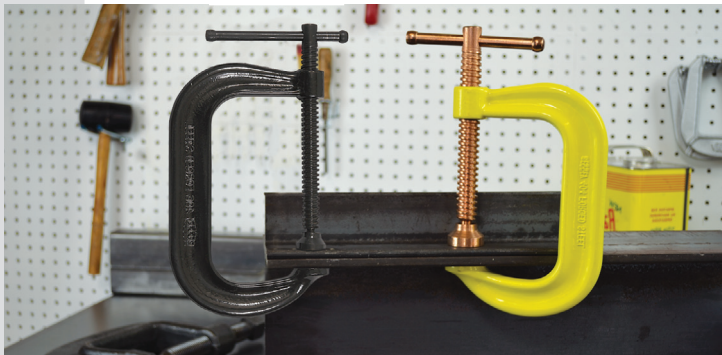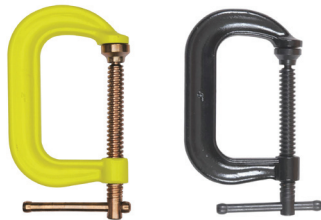

CDF Series Drop Forged C-Clamps

	Clamping Capacity	Throat Depth	Spindle Diameter	Clamping Force	
HiVis frame & copper coated spindle					
EA526ST-2A	CDF402CHV	0-2"	2 1/8"	1/2"	3500 lbs
EA526ST-3A	CDF403CHV	0-3"	2 3/8"	1/2"	3500 lbs
EA526ST-4A	CDF404CHV	0-4"	3 1/4"	3/4"	6200 lbs
EA526ST-6A	CDF406CHV	0-6"	4 1/8"	3/4"	6900 lbs
EA526ST-8A	CDF408CHV	0-8"	5"	3/4"	6900 lbs
EA526ST-10A	CDF410CHV	0-10"	6"	3/4"	8000 lbs
EA526ST-12A	CDF412CHV	0-12"	6 1/4"	3/4"	9300 lbs

Black frame & black spindle

Made in USA

EA526SR-2	CDF402	CDF402US	0-2"	2 1/8"	1/2"	3500 lbs
EA526SR-3	CDF403	CDF403US	0-3"	2 3/8"	1/2"	3500 lbs
EA526SR-4	CDF404	CDF404US	0-4"	3 1/4"	3/4"	6200 lbs
EA526SR-6	CDF406	CDF406US	0-6"	4 1/8"	3/4"	6900 lbs
EA526SR-8	CDF408	CDF408US	0-8"	5"	3/4"	6900 lbs
EA526SR-10	CDF410	CDF410US	0-10"	6"	3/4"	8000 lbs
EA526SR-12	CDF412	CDF412US	0-12"	6 1/4"	3/4"	9300 lbs

Features & Benefits

- 540 series C-clamps made of high tensile ductile alloy casting provides excellent strength in a cast clamp
- Black oxide spindle to resist corrosion



540 Series Ductile Alloy C-Clamps

	Clamping Capacity	Throat Depth	Spindle Diameter	Clamping Force
540 - 2-1/2	0 - 2 1/2"	1 3/4"	1/2"	1100 lbs
540 - 3	0 - 3"	1 7/8"	1/2"	1800 lbs
540 - 4	0 - 4"	2 1/16"	5/8"	2150 lbs
540 - 5	0 - 5"	2 1/2"	5/8"	2250 lbs
540 - 6	0 - 6"	2 3/4"	5/8"	2450 lbs
540 - 8	0 - 8"	3 1/4"	3/4"	2750 lbs
540 - 10	0 - 10"	3 5/8"	7/8"	2850 lbs
540 - 12	0 - 12"	3 5/8"	7/8"	2850 lbs
540 - 14	0 - 14"	3 3/4"	7/8"	2850 lbs



Rev. Jun/14

CDF C-Clamp Video



E-Newsletter Sign up

