




9029-9035

**ERGO™ Central Nut Wide Opening
Jaw Adjustable Wrenches with
Rubber Handle and Phosphate Finish**




PRODUCT DETAILS

- Adjustable wrenches developed according to the scientific ERGO™ process
- Extra-wide jaw opening with a shorter handle than a standard wrench offers accessibility to work in confined spaces
- Jaw will not fall out even at maximum opening of the wrench
- Head combines slim design for accessibility with strength for performance
- Laser scale in mm for pre-adjusting and accurate measurement
- Skydrol- and oil-resistant rubber handle
- High-performance alloy steel forged in single piece
- Phosphate, precision-hardened and anti-corrosion
- Left turning screw
- Standards: ISO 6787, DIN 3117, ASME B107.8-2003 and BS 6333
- Maximum comfort with minimum effort thanks to ergonomic design
- Ergonomically designed thermoplastic elastomer handle distributes pressure uniformly in the hand, reducing the risk for work related injuries
- The handle never feels too warm or too cold and tolerates oil and grease. Soft, high-friction surface reduces the risk of slipping
- Parallel jaws placed at a 15° angle provide a firm grip and best reach
- Higher capacity and accessibility with wider opening jaws and shorter handle
- Ultimate strength through precision hardening and high-performance alloy steel

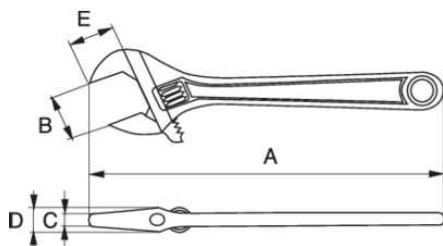

PRODUCT ATTRIBUTES

商品	A	A	B	C	D	E	 g
EA530BC-6	170 mm	6 in	32 mm	5 mm	12,8 mm	29 mm	220 g
EA530BC-7	218 mm	8 in	38 mm	5 mm	13,4 mm	34 mm	340 g
EA530BC-8	270 mm	10 in	46 mm	8 mm	17,8 mm	41 mm	525 g
EA530BC-9	324 mm	12 in	55 mm	9.5 mm	21.5 mm	50 mm	825 g

Follow the Fish!

