


ErgoTop® 92W / 99W



E92W / CBE



E99W / CBE

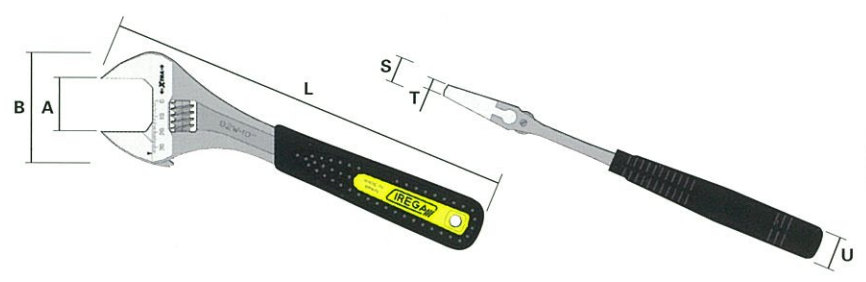

Mod. ErgoTop 92W/99W	L	A (min.)		B	S	T	U		CBE
		mm.	in.					gr.	
NEW 6"	162	24	15/16"	50	10,8	5,3	18,7	190	6
NEW 8"	209	30	1 3/16"	62	14	7,3	19,9	340	6
NEW 10"	260	34	1 3/8"	74	15,8	7,8	22,3	540	6
NEW 12"	312	39	1 1/2"	84	19	9,8	24,3	885	6

Dimensions are shown in mm unless otherwise indicated.



ErgoTop 92W
Chrome plated



ErgoTop 99W
Phosphate, left turning

SIZE	CAPACITY COMPARISON & MAXIMUM SIZE OF NUT											
	6"			8"			10"			12"		
	CAPACITY	METRIC	UNC/UNF	CAPACITY	METRIC	UNC/UNF	CAPACITY	METRIC	UNC/UNF	CAPACITY	METRIC	UNC/UNF
Standard adjustable wrench	19 mm	M12	1/2	24 mm	M16	5/8	28 mm	M18	3/4	34 mm	M22	7/8
IREGA E92W/E99W	24 mm	M16	5/8	30 mm	M20	3/4	34 mm	M22	7/8	39 mm	M24	1



IREGA, S.A.
 Fueros, 1
 48250 Zaldibar (Vizcaya) SPAIN
 Tel : (+34) 946 225 651
 Fax: (+34) 946 827 583
 irega@irega.es
 irega.es

THE IREGA GUARANTEE

All IREGA wrenches are manufactured to the highest standards and are guaranteed against any defect in workmanship or materials.

