


EA538MG-101～-116

[Y形]裸圧着端子

◆Y型(先開型)

◆材料…端子:無酸素銅(電気すずめっき)
スリーブ:無酸素銅管(電気すずめっき)

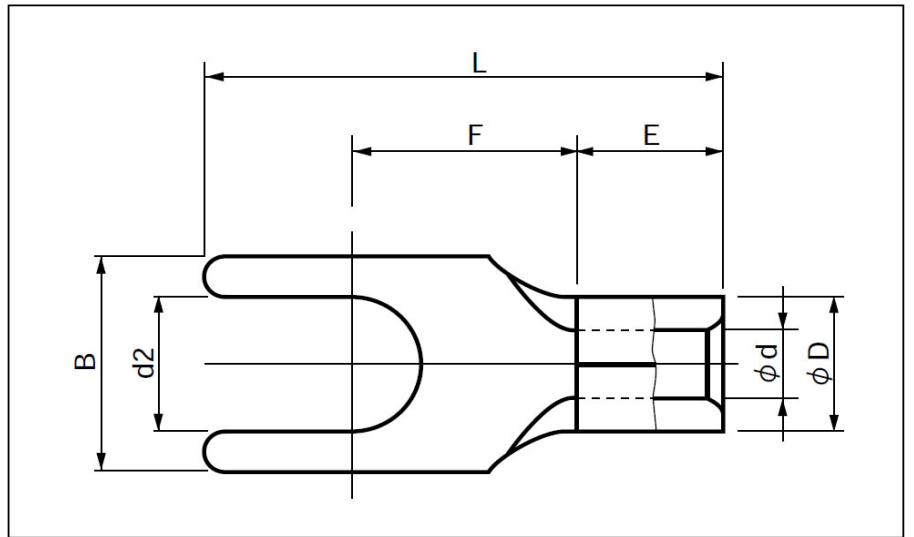

品番	型式	各部の寸法						電線抱合範囲			注)	
		ϕ d2	B	L	F	E	ϕ D	ϕ d	単線mm	撚線mm ²		AWG
EA538MG-101	0.3Y-3	3.2	5.2	12.0	4.9	4.5	2.2	1.0	-	0.2~0.5、0.3~0.5UL・CSA指定	24-20、22-20UL・CSA指定	◎
EA538MG-102	0.3Y-5	5.3	8.0	15.5	7.0							
EA538MG-103	1.25Y-3	3.2	5.8	15.0	5.8							
EA538MG-104	1.25Y-4N	4.3	6.4	16.4	6.6							
EA538MG-105	1.25Y-4M		8.1		7.5							
EA538MG-106	1.25Y-5	5.3	9.6	17.5	8.3							
EA538MG-107	2Y-3	3.2	5.9	15.8	6.6							
EA538MG-108	2Y-4	4.3	8.0	16.0	7.1							
EA538MG-109	2Y-5	5.3										
EA538MG-110	3.5Y-4	4.3		18.0	7.2		6.0	5.0	3.0	1.82~2.4	2.63~4.6	
EA538MG-111	3.5Y-5	5.3	9.5	20.0	8.3							
EA538MG-112	5.5Y-4	4.3	9.0	18.2	7.2							
EA538MG-113	5.5Y-5	5.2										
EA538MG-114	5.5Y-6	6.4		12.5	25.2	12.0						
EA538MG-115	8Y-6	6.4	16.0	31.7	14.5	10.0	9.0	5.8	-	10.52~16.78	6	
EA538MG-116	14Y-8	8.4		31.2								

注)◎:UL・CSA登録品

○: UL、CSA登録品

◆取得規格

- ・UL486A(WIRE CONNECTORS AND SOLDERING LUGS FOR COPPER CONDUCTORS)に適合
- ・UL ファイルNo.E44245にて承認
- ・CSA C22.2(CONSTRUCTION AND TEST OF WIRE CONNECTORS)に適合
- ・CSA ファイルNo.LR-28418にて承認