


サーモキャップ寸法

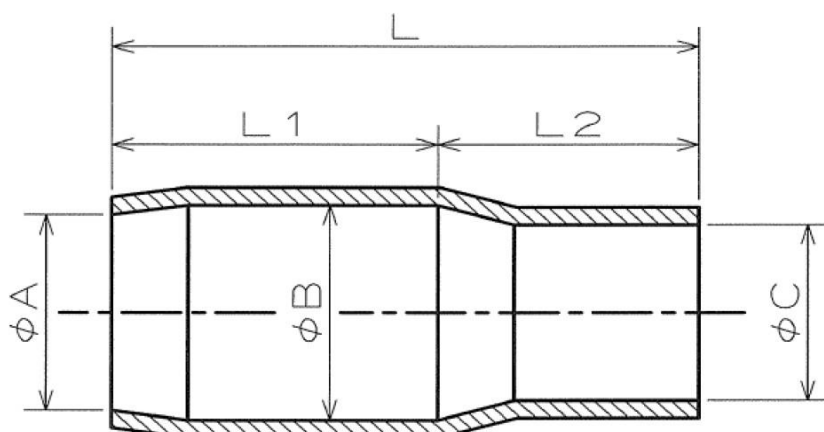

公差 品番	±1.0 ΦA	±1.0 ΦB	±1.0 ΦC	±0.5 L1	±1.5 L2	±2.0 L	±0.3 t
EA538SA-1 EA538SB-1 EA538SC-1	3.3	4.5	3.7	6.0	7.0	13.0	0.8
EA538SA-2 EA538SB-2 EA538SC-2	5.5	6.4	5.0	9.0	8.0	17.0	0.8
EA538SA-3 EA538SB-3 EA538SC-3	6.2	7.2	6.2	10.0	9.0	19.0	1.0
EA538SA-4 EA538SB-4 EA538SC-4	8.0	10.0	8.0	14.0	10.0	24.0	1.0
EA538SA-5 EA538SB-5 EA538SC-5	9.5	12.0	9.5	15.5	14.0	29.5	1.2
EA538SA-6 EA538SB-6 EA538SC-6	12.0	14.0	12.0	17.0	15.0	32.0	1.2
EA538SA-7 EA538SB-7 EA538SC-7	14.0	17.0	14.0	21.0	17.0	38.0	1.5
EA538SA-8 EA538SB-8 EA538SC-8	20.0	22.0	18.0	30.0	22.0	52.0	1.8
EA538SA-9 EA538SB-9 EA538SC-9	27.5	32.0	24.5	36.0	32.0	68.0	2.0
EA538SA-10 EA538SB-10 EA538SC-10	35.0	37.5	30.0	42.0	31.0	73.0	2.0

単位:(mm)