


## EA573-0.7~-22

(六角棒レンチ)

○ クロームバナジウム鋼

サイズ1.5mm以上はクロームメッキ仕上げ

○ 硬度…HRC59

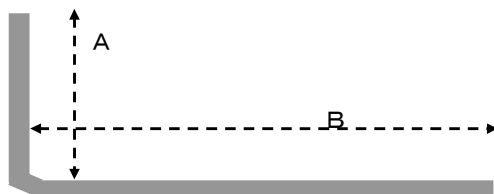

	対辺(mm)	A	B	重量(g)
-0.7	0.71	7	35	0.2
-0.9	0.89	10	40	0.3
-1.3	1.27	12	45	0.5
-1.5	1.5	14	50	1
-2	2	16	56	2
-2.5	2.5	18	63	3
-3	3	20	71	5
-3.5	3.5	21	75	8
-4	4	22	80	11
-4.5	4.5	23	85	15
-5	5	25	90	19
-5.5	5.5	26	95	24
-6	6	28	100	31
-7	7	30	105	44
-8	8	32	112	62
-9	9	34	115	81
-10	10	36	125	109
-12	12	40	140	175
-14	14	45	160	272
-17	17	50	180	454
-19	19	56	200	642
-22	22	63	224	958

(mm)