


EA573MJ-6~-25 [BoreTorx] キーレンチ

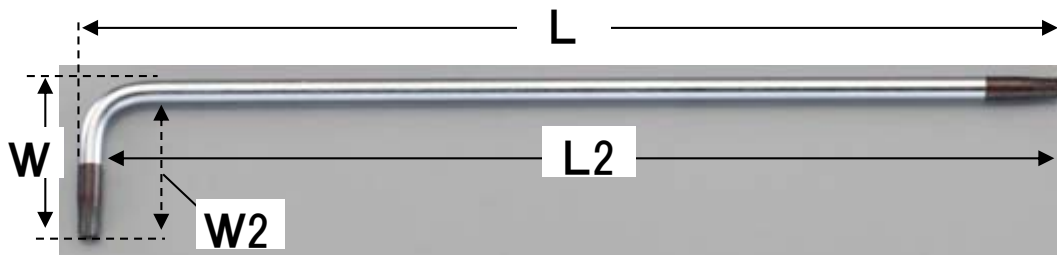

●イジリ止付



廃番
廃番
廃番
廃番

品番	サイズ	L(全長)	L2(軸長)	W	W2	軸径(φ)	重量(g)
EA573MJ-6	T6	82.5	80.0	17.5	15.0	2.5	3
EA573MJ-7	T7	92.5	90.0	18.5	16.0	2.5	4
EA573MJ-8	T8	102.5	100.0	20.0	17.5	2.5	5
EA573MJ-9	T9	113.0	110.0	20.5	17.5	3.0	7
EA573MJ-10	T10	123.5	120.0	21.5	18.0	3.5	10
EA573MJ-15	T15	138.5	135.0	23.5	20.0	3.5	11
EA573MJ-20	T20	154.0	150.0	25.5	21.5	4.0	16
EA573MJ-25	T25	170.0	165.0	27.0	22.0	5.0	28

単位 (mm)

●材質…クロムバナジウム鋼