

## EA580WC

## Duo-Crimp No. 300

WEICON has been developing and producing various types of cable stripper since 1967. These premium quality tools are TÜV-tested, carry the GS seal for verified safety, and were developed taking occupational safety and user-friendliness aspects into account. The WEICON range includes cable strippers, cable dismantling tools, wire strippers and various multifunctional tools for professional users.

**Description**

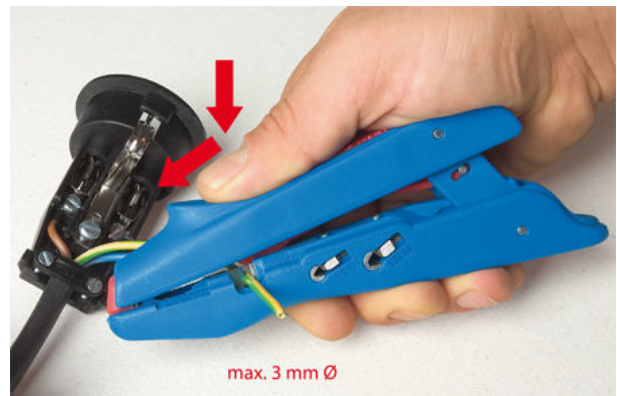
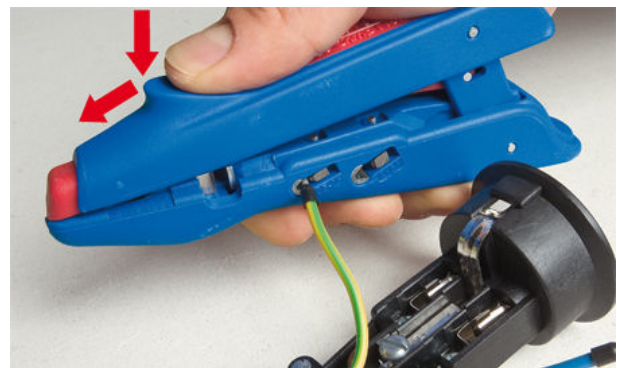
The WEICON multi-functional tools offer a large number of options for stripping a wide range of cable types. The product family of the tools includes various types, which have different additional functions and thus meet the individual needs of the users.



The WEICON Duo-Crimp No. 300 can be used to strip conductors and crimp terminals. The automatic scanning system means that there is no need to adjust to the cable cross-section. The stripper has an optical length scale from 8 – 20 mm and is suitable for all flexible and solid conductors of 0.5 mm<sup>2</sup> - 6.0 mm<sup>2</sup>. The Duo-Crimp No. 300 strips conductors at a length of 5 mm, preventing the individual conductors from splaying. The conductor can then be twisted. Two crimping ranges of 0.5 – 2.5 mm<sup>2</sup> and 4.0 – 6.0 mm<sup>2</sup> are available for crimping terminals. An easy-to-reach side cutter is integrated into the Duo-Crimp No. 300 and can be used up to a cable diameter of 6 mm (solid conductors up to 4 mm).

**Technical data**

Cable type	Fine-wired and solid conductors with PVC insulation
Field of use	0,5 – 6,0 mm <sup>2</sup>
Inner blade	Replaceable
Additional benefits	Side cutter, solid up to 4.0mm <sup>2</sup> , flexible up to 6.0mm <sup>2</sup>
Additional functions	Terminal crimping 0.5 - 2.5mm <sup>2</sup> and 4.0 - 6.0mm <sup>2</sup>
Approval/certificates	Safety tested by TÜV NORD
Material	Glass fibre reinforced polyamide
Length	160 mm
Weight	115 gr
Accessories	Replacement blade set, item no. 51953020


**Note**

Working with WEICON Stripping tools is only permitted with potential free wires and conduction.

**WEICON GmbH & Co. KG  
(Headquarter)**

Königsberger Str. 255 · DE-48157 Münster  
P.O. Box 84 60 · DE-48045 Münster  
Germany

Tel. +49 (0) 251 / 93 22-0  
Fax +49 (0) 251 / 93 22-244  
Fax +49 (0) 251 / 93 22-233 Export  
www.weicon.de · info@weicon.de

**WEICON Middle East L.L.C.**

Jebel Ali Ind Area 3 · P.O. Box 118 216  
Dubai · U.A.E

Phone +971 4 880 25 05  
Fax +971 4 880 25 09  
Mobile +971 50 545 99 83  
www.weicon.ae · info@weicon.ae

**WEICON Inc.**

20 Steckle Place · Unit 20  
Kitchener · Ontario · N2E 2C3  
Canada

Phone +1 519 896 5252  
Fax +1 519 896 5254  
Cell +1 519 590 5168  
www.weicon.ca · info@weicon.ca

**WEICON Kimya Sanayi Tic. Ltd. Şti.**

Yenibosna Mahallesi Yalçın Koreş Caddesi  
Arifağa Sokak No: 29 Kat: 3  
34530 Yenibosna – İstanbul Turkey  
www.weicon.biz.tr · info@weicon.biz.tr

**WEICON Romania SRL**

Str. Podului Nr.1  
547176 Budiu Mic (Targu Mures)  
www.weicon.com · office@weicon.com