


## KS 片ラチェットスパナ

Ratchet

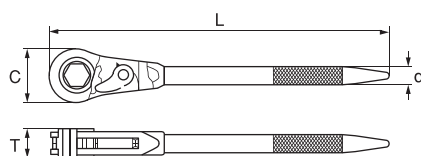


Code	mm	C mm	T mm	d mm	L mm	歯数	重量 g	箱入数	
KS0017	17	36	35	13	220	12	330	2	EA602AP-17
KS0019	19	42	42	15	270	12	550	2	EA602AP-19
KS0021	21	42	42	15	270	12	550	2	EA602AP-21
KS0022	22	42	42	15	270	12	550	2	EA602AP-22
KS0024	24	49	48	18	325	12	880	2	EA602AP-24
KS0026	26	49	48	18	325	12	880	2	EA602AP-26
KS0027	27	49	48	18	325	12	880	2	EA602AP-27
KS0030	30	57	53	20	430	12	1,450	2	EA602AP-30
KS0032	32	57	53	20	430	12	1,450	2	EA602AP-32
KS0035	35	67	60	24	535	12	2,500	2	EA602AP-35
KS0036	36	67	60	24	535	12	2,500	2	EA602AP-36
KS0041	41	72	60	24	560	12	2,520	2	EA602AP-41
KS0046	46	82	65	26	590	14	3,400	2	EA602AP-46
KS0050	50	87	65	28	645	14	4,000	2	EA602AP-50
KS0055	55	97	65	30	760	16	5,500	-	
KS0060	60	102	70	32	800	16	6,500	-	
KS0065	65	113	75	34	910	16	7,000	-	
KS0070	70	122	80	38.1	910	16	8,300	-	
KS0075	75	130	80	38.1	965	16	9,000	-	
KS0080	80	143	80	48.6	1,160	18	13,000	-	

- ・片爪タイプ
- ・60mm 以上は受注生産品

## KL 四角ラチェットスパナ (両爪)

Ratchet

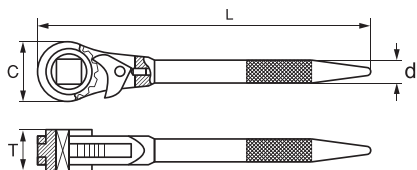


Code	mm	C mm	T mm	d mm	L mm	歯数	重量 g	箱入数	
KL0010	10	28	17	10	200	10	210	3	EA602AR-10
KL0012	12	36	20	12	245	10	350	3	EA602AR-12
KL0013	13	36	20	12	245	10	350	3	EA602AR-13
KL0014	14	42	24	14	295	10	550	3	EA602AR-14
KL0016	16	42	24	14	295	10	520	3	EA602AR-16
KL0017	17	49	28	15	385	10	850	3	EA602AR-17
KL0019	19	49	28	19	385	10	880	3	EA602AR-19
KL0022	22	57	30	22	400	10	1,400	3	EA602AR-22
KL0024	24	67	32	22	500	10	2,150	3	EA602AR-24
KL0025	25	67	32	22	500	10	2,300	3	EA602AR-25

- ・両爪タイプ

## KKL 四角ラチェットスパナ (片爪)

Ratchet

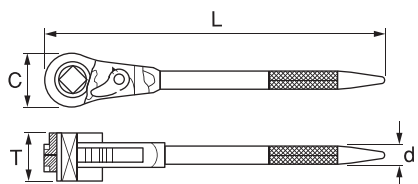

Code	mm	C mm	T mm	d mm	L mm	歯数	重量 g	箱入数	
KKL0013	13	36	20	13	220	12	320	3	
KKL0016	16	42	24	15	270	12	520	3	
KKL0019	19	49	28	18	325	12	860	3	
KKL0022	22	57	30	20	430	12	1,400	3	
KKL0025	25	67	32	24	535	12	2,300	3	
KKL0028	28	72	33	24	555	14	2,500	3	
KKL0032	32	82	37	26	590	14	3,270	3	

- ・片爪タイプ