


## KS 片ラチェットスパナ

Ratchet

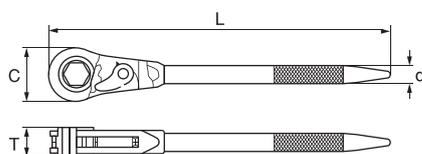


| Code   | mm | C mm | T mm | d mm | L mm  | 歯数 | 重量 g   | 箱入数 |            |
|--------|----|------|------|------|-------|----|--------|-----|------------|
| KS0017 | 17 | 36   | 35   | 13   | 220   | 12 | 330    | 2   | EA602AP-17 |
| KS0019 | 19 | 42   | 42   | 15   | 270   | 12 | 550    | 2   | EA602AP-19 |
| KS0021 | 21 | 42   | 42   | 15   | 270   | 12 | 550    | 2   | EA602AP-21 |
| KS0022 | 22 | 42   | 42   | 15   | 270   | 12 | 550    | 2   | EA602AP-22 |
| KS0024 | 24 | 49   | 48   | 18   | 325   | 12 | 880    | 2   | EA602AP-24 |
| KS0026 | 26 | 49   | 48   | 18   | 325   | 12 | 880    | 2   | EA602AP-26 |
| KS0027 | 27 | 49   | 48   | 18   | 325   | 12 | 880    | 2   | EA602AP-27 |
| KS0030 | 30 | 57   | 53   | 20   | 430   | 12 | 1,450  | 2   | EA602AP-30 |
| KS0032 | 32 | 57   | 53   | 20   | 430   | 12 | 1,450  | 2   | EA602AP-32 |
| KS0035 | 35 | 67   | 60   | 24   | 535   | 12 | 2,500  | 2   | EA602AP-35 |
| KS0036 | 36 | 67   | 60   | 24   | 535   | 12 | 2,500  | 2   | EA602AP-36 |
| KS0041 | 41 | 72   | 60   | 24   | 560   | 12 | 2,520  | 2   | EA602AP-41 |
| KS0046 | 46 | 82   | 65   | 26   | 590   | 14 | 3,400  | 2   | EA602AP-46 |
| KS0050 | 50 | 87   | 65   | 28   | 645   | 14 | 4,000  | 2   | EA602AP-50 |
| KS0055 | 55 | 97   | 65   | 30   | 760   | 16 | 5,500  | -   |            |
| KS0060 | 60 | 102  | 70   | 32   | 800   | 16 | 6,500  | -   |            |
| KS0065 | 65 | 113  | 75   | 34   | 910   | 16 | 7,000  | -   |            |
| KS0070 | 70 | 122  | 80   | 38.1 | 910   | 16 | 8,300  | -   |            |
| KS0075 | 75 | 130  | 80   | 38.1 | 965   | 16 | 9,000  | -   |            |
| KS0080 | 80 | 143  | 80   | 48.6 | 1,160 | 18 | 13,000 | -   |            |

- ・片爪タイプ
- ・60mm 以上は受注生産品

## KL 四角ラチェットスパナ (両爪)

Ratchet

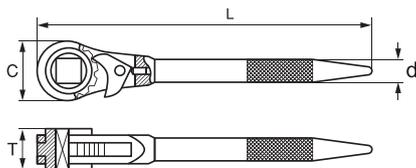


| Code   | mm | C mm | T mm | d mm | L mm | 歯数 | 重量 g  | 箱入数 |            |
|--------|----|------|------|------|------|----|-------|-----|------------|
| KL0010 | 10 | 28   | 17   | 10   | 200  | 10 | 210   | 3   | EA602AR-10 |
| KL0012 | 12 | 36   | 20   | 12   | 245  | 10 | 350   | 3   | EA602AR-12 |
| KL0013 | 13 | 36   | 20   | 12   | 245  | 10 | 350   | 3   | EA602AR-13 |
| KL0014 | 14 | 42   | 24   | 14   | 295  | 10 | 550   | 3   | EA602AR-14 |
| KL0016 | 16 | 42   | 24   | 14   | 295  | 10 | 520   | 3   | EA602AR-16 |
| KL0017 | 17 | 49   | 28   | 15   | 385  | 10 | 850   | 3   | EA602AR-17 |
| KL0019 | 19 | 49   | 28   | 19   | 385  | 10 | 880   | 3   | EA602AR-19 |
| KL0022 | 22 | 57   | 30   | 22   | 400  | 10 | 1,400 | 3   | EA602AR-22 |
| KL0024 | 24 | 67   | 32   | 22   | 500  | 10 | 2,150 | 3   | EA602AR-24 |
| KL0025 | 25 | 67   | 32   | 22   | 500  | 10 | 2,300 | 3   | EA602AR-25 |

- ・両爪タイプ

## KKL 四角ラチェットスパナ (片爪)

Ratchet

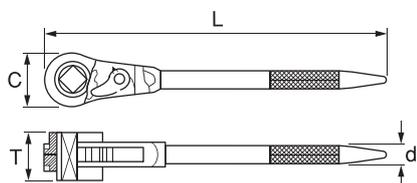

| Code    | mm | C mm | T mm | d mm | L mm | 歯数 | 重量 g  | 箱入数 |  |
|---------|----|------|------|------|------|----|-------|-----|--|
| KKL0013 | 13 | 36   | 20   | 13   | 220  | 12 | 320   | 3   |  |
| KKL0016 | 16 | 42   | 24   | 15   | 270  | 12 | 520   | 3   |  |
| KKL0019 | 19 | 49   | 28   | 18   | 325  | 12 | 860   | 3   |  |
| KKL0022 | 22 | 57   | 30   | 20   | 430  | 12 | 1,400 | 3   |  |
| KKL0025 | 25 | 67   | 32   | 24   | 535  | 12 | 2,300 | 3   |  |
| KKL0028 | 28 | 72   | 33   | 24   | 555  | 14 | 2,500 | 3   |  |
| KKL0032 | 32 | 82   | 37   | 26   | 590  | 14 | 3,270 | 3   |  |

- ・片爪タイプ