
 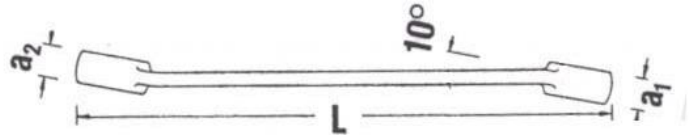


EA605AA-1~10

(オープンリングスパナ)

○ クロム合金鋼

○ AA-1~AA-4は6ポイント 他は12ポイント



	対辺	L	d1	d2	a1	a2	m1	m2	重量 (g)	
AA-1	8X10	145	17.5	19.5	7	8.5	6.3	7.1	39	
AA-1B	9X11	155	18.5	21.5	8.5	9	6.7	8.6	54	
AA-1C	10X11	155	19.5	21.5	8.5	9	7.1	8.6	55	
AA-2	10X12	160	19.5	22.5	8.5	9.5	7.1	9	59	
AA-3	11X13	170	21.5	24	9	10	8.6	10	80	
AA-4	14X14	180	24	26	9.5	10.5	9	11	89	
AA-4B	14X17	200	26	30	10.5	12	11	14	115	
AA-4C	16X19	220	29	33	12	13	13	15.8	155	廃番
AA-5	17X19	220	30	33	12	13	14	15.8	151	
AA-5B	18X21	230	31.5	35.5	13	13.5	14.8	16.2	182	廃番
AA-6	21X23	235	35.5	38.5	13.5	15	16.2	17.5	192	廃番
AA-7	22X24	245	37	40.5	15	16	17	18	251	
AA-8	24X27	270	40.5	44.5	16	17.5	18	20	310	
AA-9	27X36	300	42	54	16	19	20	27	414	
AA-10	30X32	300	48.5	50.5	20	22	22	24	455	

(単位mm)