


EA614CD-1 ~ -17 片目片口スパナ

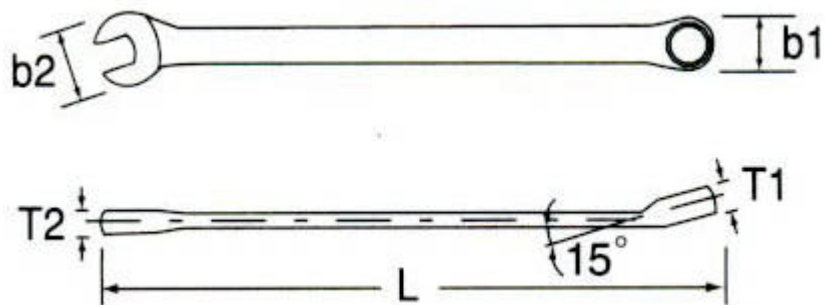

(mm)

| 品番         | サイズ     | b1   | b2 | T1   | T2   | L   |
|------------|---------|------|----|------|------|-----|
| EA614CD-1  | 1/4"    | 11.5 | 12 | 5    | 4.5  | 128 |
| EA614CD-2  | 5/16"   | 13.5 | 16 | 5    | 4    | 140 |
| EA614CD-3  | 11/32"  | 15   | 19 | 6.3  | 5.1  | 150 |
| EA614CD-4  | 3/8"    | 15.5 | 21 | 6    | 4    | 160 |
| EA614CD-5  | 7/16"   | 17   | 23 | 6    | 5    | 165 |
| EA614CD-6  | 1/2"    | 20   | 27 | 8.5  | 6.5  | 180 |
| EA614CD-7  | 9/16"   | 21   | 28 | 8.5  | 6.5  | 190 |
| EA614CD-8  | 5/8"    | 24   | 33 | 10   | 6.5  | 210 |
| EA614CD-9  | 11/16"  | 26   | 35 | 10   | 7    | 225 |
| EA614CD-10 | 3/4"    | 28   | 39 | 10.8 | 8    | 250 |
| EA614CD-11 | 13/16"  | 30   | 43 | 12   | 8.5  | 270 |
| EA614CD-12 | 7/8"    | 32   | 45 | 12.5 | 9    | 290 |
| EA614CD-13 | 15/16"  | 34   | 49 | 13.5 | 9.5  | 310 |
| EA614CD-14 | 1"      | 35   | 52 | 14   | 10   | 330 |
| EA614CD-15 | 1 1/16" | 38   | 59 | 15   | 10.5 | 355 |
| EA614CD-16 | 1 1/8"  | 42   | 62 | 16.5 | 11.5 | 400 |
| EA614CD-17 | 1 1/4"  | 45   | 66 | 17   | 12   | 420 |

12ポイント

オフセット角は15度です。

材質...クロームバナジウム鋼