


EA614DA-5.5~-32

ギアレレンチ



- 材質…クロムバナジウム鋼
- ギアレレンチ
- レンチの裏表を変更することで、ナット類の締め・緩めに対応出来ます。

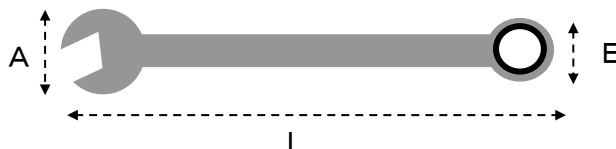

品番	サイズ*	L	A	A厚	B	B厚	重さ(g)	送り角
EA614DA-5.5	5.5	127	13.5	5.3	16	6.7	29	6°
EA614DA-6	6	127	13.5	5.8	16	6.7	24	6°
EA614DA-7	7	142	14.6	6.3	16	6.7	33	6°
EA614DA-8	8	142	16.7	6.3	16	7.1	40	6°
EA614DA-9	9	152	18.8	6.6	17.5	7.1	43	6°
EA614DA-10	10	161	20.9	6.9	19	7.9	57	5°
EA614DA-11	11	167	23	7.1	20.6	8.4	72	5°
EA614DA-12	12	173	25.1	8	21.7	8.8	89	5°
EA614DA-13	13	180	27.2	8.9	23.6	8.8	100	5°
EA614DA-14	14	192	29.3	8.9	25.9	9.6	121	5°
EA614DA-15	15	201	31.3	8.9	27.2	10.1	136	5°
EA614DA-16	16	210	33.4	9.6	28.7	10.5	158	5°
EA614DA-17	17	227	35.5	9.8	30.5	10.9	191	5°
EA614DA-18	18	238	37.6	10	31.5	11.4	211	5°
EA614DA-19	19	250	39.7	10.3	34	11.4	233	5°
EA614DA-21	21	290	46	10.4	38	13.2	354	5°
EA614DA-22	22	290	46	10.4	39	13.2	328	5°
EA614DA-24	24	334	52.2	11.2	45.5	14.7	458	5°
EA614DA-27	27	356	56.4	11.8	49	15.7	598	5°
EA614DA-30	30	403	62.7	12.8	54	17.2	812	5°
EA614DA-32	32	425	66.8	13.2	58	17.7	975	5°

(単位mm)