


**EA614LK - 8 ~ - 19**  
 (コンビネーションギヤレンチ)

工具鋼製  
 ヘッド部が180°回転

送り角度5°(キヤ山数72山)  
 本締め可能  
 12ポイント

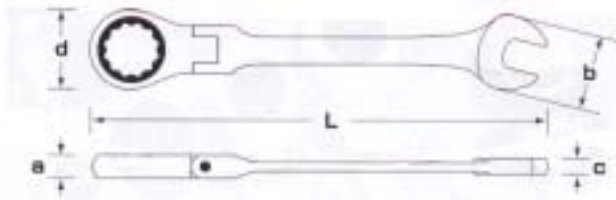

	サイズ	L	d	b	a	c
LK - 8	8	140	15.9	16.5	6.5	4.5
LK - 9	9	150	17.5	18.8	6.9	4.7
LK - 10	10	158	19.1	20.5	7.5	5.1
LK - 11	11	165	20.5	23	7.7	5.5
LK - 12	12	171	21.7	25	8	5.5
LK - 13	13	178	23.6	27	8.5	6.1
LK - 14	14	190	25.9	29.5	9	6.5
LK - 15	15	199	26.7	31.3	9.4	6.8
LK - 16	16	208	28.4	33.4	9.9	7.1
LK - 17	17	225	30.5	35.5	10.3	7.5
LK - 18	18	236	31.5	37.6	10.7	8
LK - 19	19	248	32.5	39.7	11.2	8.5

(単位mm)