


EA614LT-8~-109 フレックススタビークリアレンチ

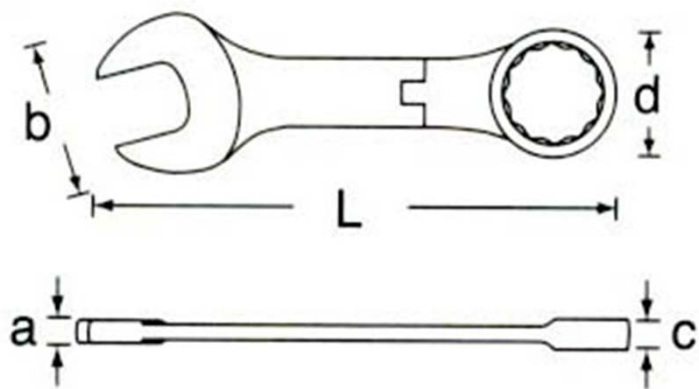

(mm)

品番	サイズ	a	b	d	L
EA614L T-8	8	5	16.5	17	88
EA614L T-9	9	5.2	19	18.5	92
EA614L T-10	10	5.6	20.1	19	94
EA614L T-11	11	6	23	20.6	102
EA614L T-12	12	6.4	25.1	21.7	105
EA614L T-13	13	6.7	27.2	23.6	107
EA614L T-14	14	7.1	29.3	25.9	114
EA614L T-15	15	7.4	31.3	27.2	118
EA614L T-16	16	8.4	33.4	28.7	122
EA614L T-17	17	8.1	35.5	30.5	126
EA614L T-18	18	8.5	37.6	31.5	130
EA614L T-19	19	9.1	39.7	32.5	138
EA614L T-101	5/16"	5	16.5	17	88
EA614L T-102	11/32"	5.2	19	18.5	92
EA614L T-103	3/8"	5.6	20.1	19	94
EA614L T-104	7/16"	6	23	20.6	102
EA614L T-105	1/2"	6.7	25.1	23.6	107
EA614L T-106	9/16"	7.1	29.3	25.9	114
EA614L T-107	5/8"	7.7	33.4	28.7	122
EA614L T-108	11/16"	8.1	35.5	30.5	126
EA614L T-109	3/4"	9.1	39.7	32.5	138

廃番

廃番

廃番

廃番

廃番

廃番

廃番

廃番

廃番

●12ポイント

●材質…クロームバナジウム鋼

●細かい作業や低トルクの作業に！