
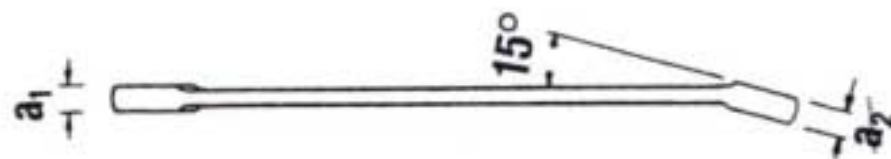


|                        | サイズ | L  | b    | d   | a1 | a2  | 重量(g) |
|------------------------|-----|----|------|-----|----|-----|-------|
| EA614SS-3.2            | 3.2 | 75 | 10   | 6.6 | 3  | 3.2 | 6     |
| EA614SS-3.5            | 3.5 | 75 | 10   | 6.6 | 3  | 3.2 | 6     |
| EA614SS-4              | 4   | 85 | 12.5 | 7.8 | 3  | 3.2 | 9     |
| EA614SS-4.5            | 4.5 | 85 | 12.5 | 7.8 | 3  | 3.2 | 8     |
| EA614SS-5<br>(片目片ロスパナ) | 5   | 95 | 14   | 9.8 | 3  | 3.2 | 11    |

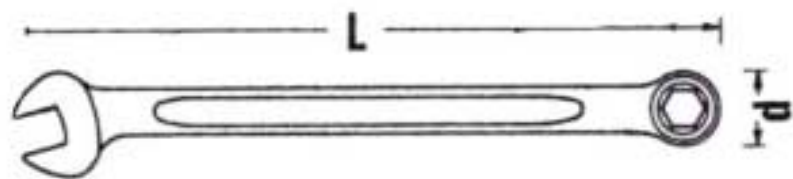

○ クロム合金鋼